


Series variation

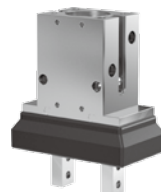

Linear Slide Hand LSH-HP Series

LCM
 LCR
 LCG
 LCW
 LCX
 STM
 STG
 STS/STL
 STR2
 UCA2
 ULK*
 JSK/M2
 JSG
 JSC3/JSC4
 USSD
 UFCD
 USC
 UB
 JSB3
 LMB
 LML
 HCM
 HCA
 LBC
 CAC4
 UCAC2
 CAC-N
 UCAC-N
 RCS2
 RCC2
 PCC
 SHC
 MCP
 GLC
 MFC
 BBS
 RRC
 GRC
 RV3*
 NHS
 HRL
 LN
Hand
 Chuk
 MecHnd/Chuk
 ShkAbs
 FJ
 FK
 SpdContr
 Ending
LSH-HP
 LSH
 FH100
 BSA2
 BHA/BHG
 LHA
 LHAG
 HAP
 HKP
 HCP
 HGP
 HLF2
 HLA/HLB
 HLAG/HLBG
 HLC
 HLD
 HMF
 HMF-G
 HMFB
 HFP
 FH500
 HBL
 HJL
 HMD
 HDL
 HJD
 BHE

Variation		Model No.	Bore size (mm)
HP1 Series	Double acting/single acting without rubber cover 	LSH-A	ø6
			ø10
			ø16
			ø20
			ø25
			ø32
	Double acting/single acting with rubber cover 	LSH-G LSH-F	ø6
			ø10
			ø16
			ø20
			ø25
			ø32
	Double acting long stroke length without rubber cover 	LSHL-A	ø10
			ø16
			ø20
			ø25
	Double acting long stroke length with rubber cover 	LSHL-G LSHL-F	ø10
			ø16
			ø20
HP2 Series	With length measuring function, double acting without rubber cover 	LSHM-A	ø10
			ø16
			ø20
			ø25
	With length measuring function, double acting with rubber cover 	LSHM-G LSHM-F	ø10
			ø16
			ø20
			ø25

- Positional reference of positioning hole 1567
- Model selection..... 1568
- Technical data 1570
- Cylinder switch precautions 1576

	Gripping power (N)					Operating stroke length (mm)	Switch model No.	Page
	5	10	50	100	200			
						4	F2S	1512
						6		
						10		
						14		
						22		
						4	F3S	1522
						6	F2H/V	
						10	F3H/V	
						14	F3PH/V	
						22	T2H/V	
						8	T3H/V	1532
						12	T2H/VR3	
						18		
						22	T3PH/V	
						8		1540
						12		
						18		
						4	—	1546
						6		
						10		
						14		
						4	—	1554
						6		
						10		
						14		

*Range of gripping power at supply pressure 0.5 MPa and finger length 20 mm

LCM
LCR
LCG
LCW
LCX
STM
STG
STS/STL
STR2
UCA2
ULK*
JSK/M2
JSG
JSC3/JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3*
NHS
HRL
LN
Hand
Chuk
MechHnd/Chuk
ShkAbs
FJ
FK
SpdContr
Ending
LSH-HP
LSH
FH100
BSA2
BHABHG
LHA
LHAG
HAP
HKP
HCP
HGP
HLF2
HLA/HLB
HLAGHLBG
HLC
HLD
HMF
HMF-G
HMFB
HFP
FH500
HBL
HJL
HMD
HDL
HJD
BHE