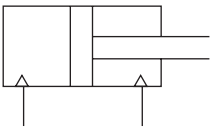
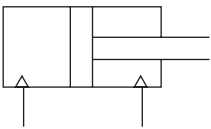
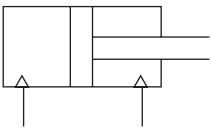


Series variation

Rotary clamp cylinder RCS2 Series

LCM
LCR
LCG
LCW
LCX
STM
STG
STS/STL
STR2
UCA2
ULK*
JSK/M2
JSG
JSC3/JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3*
NHS
HRL
LN
Hand
Chuk
MecHnd/Chuk
ShkAbs
FJ
FK
SpdContr
Ending

Variation	Model No. JIS symbol	Bore size (mm)	Stroke (mm)								
			17.5	19.5	25	29	27.5	29.5	35	39	
Double acting/single rod	RCS2 	ø12/ø16	●				●				
		ø20/ø25		●				●			
		ø32/ø40			●				●		
		ø50/ø63				●				●	
Double acting Packing material fluoro rubber	RCS2-T2 	ø12/ø16	●				●				
		ø20/ø25		●				●			
		ø32/ø40			●				●		
		ø50/ø63				●				●	
Double acting Anti-spatter adherence	RCS2-G4 	ø32/ø40			●				●		
		ø50/ø63				●				●	

●: Standard, ○: Option, ■: Not available

	Stroke (mm)						Rotary stroke (mm)	Clamp stroke (mm)	Mounting			Option	Accessory	Switch	Page
									Basic	Rod side flange	Head side flange	Spigot at head side	Clamp lever		
	37.5	39.5	45	49	65	69	(mm)	(mm)	00	FA	FB	H	A		
	●	■	■	■	■	■	7.5	10/20/30	○	○	○	○	○	○	1068
	■	●	■	■	■	■	9.5								
	■	■	●	■	●	■	15								
	■	■	■	●	■	●	19	30 / 50							
	●	■	■	■	■	■	7.5	10/20/30	○	○	○	○	○	○	1078
	■	●	■	■	■	■	9.5								
	■	■	●	■	●	■	15								
	■	■	■	●	■	●	19	30 / 50							
	■	■	●	■	●	■	15	10/20/30	○	○	○	○	○	○	1084
	■	■	■	●	■	●	19	30 / 50							

LCM
LCR
LCG
LCW
LCX
STM
STG
STS/STL
STR2
UCA2
ULK*
JSK/M2
JSG
JSC3/JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3*
NHS
HRL
LN
Hand
Chuk
MechHnd/Chuk
ShkAbs
FJ
FK
SpdContr
Ending