


Variation and option combination selection table

- ◎ : Option
 ○ : Available (made-to-order product)
 △ : Available depending on conditions (Contact CKD.)
 × : Not available

Category		Category	Variation		Port thread		Option	
			Double acting basic	With cylinder switch	NPT	G	Specify piston rod end form	
		Code	None	None	N	G	N*	
Variation	Double acting basic	Blank	◎		○	○	○	
	With cylinder switch	Blank			○	○	○	
Port thread	NPT	N				×	○	
	G	G					○	
Option	Specify piston rod end form	N*						
Accessory	Cylinder switch	Listed separately	◎	◎	○	○	○	
	Rod eye	I	◎	◎	○	○	△	
	Rod clevis	Y	◎	◎	○	○	△	

[Example of model No.]

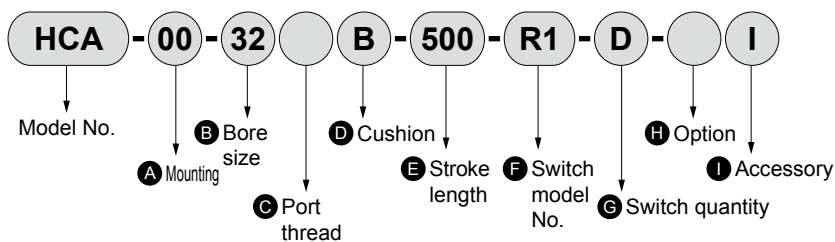

Model No.: High speed cylinder

- Variation : Double acting, basic with switch
- A Mounting : Basic
- B Bore size : ø32 mm
- C Port thread : Rc thread
- D Cushion : Both sides cushioned
- E Stroke length : 500 mm
- F Switch model No.: Proximity R1 switch, lead wire 1 m
- G Switch quantity : 2
- H Option : None
- I Accessory : Rod eye