
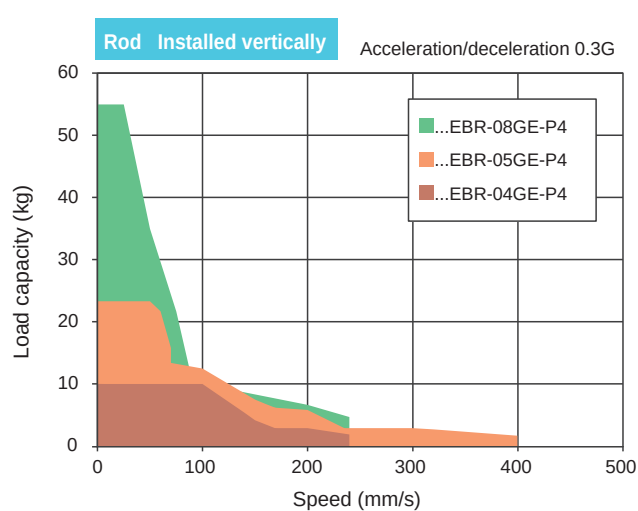


EBR-G-P4 Series

Series variation

Controller	Actuator model No.		Motor size	Motor mounting direction	Body width (mm)	Screw lead (mm)	Max. load capacity (kg)		Maximum pushing force (N)	
							Horizontal	Vertical		
  ECG Series		EBR-04GE-06-P4	□35	Straight	44	6	40.0	10.0	155	
		EBR-04GE-12-P4				12	12.5	2.9	77	
		EBR-04GR/D/L-06-P4		Left/Right/Bottom		6	40.0	8.3	155	
		EBR-04GR/D/L-12-P4				12	12.5	2.9	77	
		EBR-05GE-02-P4	□42	Straight	54	2	80.0	23.3	550	
		EBR-05GE-05-P4				5	60.0	14.0	220	
		EBR-05GE-10-P4				10	41.7	7.0	110	
		EBR-05GE-20-P4				20	11.7	2.9	55	
		EBR-05GR/D/L-02-P4		Left/Right/Bottom		2	80.0	23.3	550	
		EBR-05GR/D/L-05-P4				5	60.0	14.0	220	
		EBR-05GR/D/L-10-P4				10	38.3	6.7	110	
		EBR-05GR/D/L-20-P4				20	11.7	1.7	55	
		EBR-08GE-05-P4	□56	Straight	82	5	80.0	55.0	965	
		EBR-08GE-10-P4				10	70.0	23.3	482	
		EBR-08GE-20-P4				20	35.0	10.0	241	
		EBR-08GR/D/L-05-P4		Left/Right/Bottom		5	80.0	55.0	965	
		EBR-08GR/D/L-10-P4				10	70.0	20.0	482	
		EBR-08GR/D/L-20-P4				20	35.0	8.3	241	

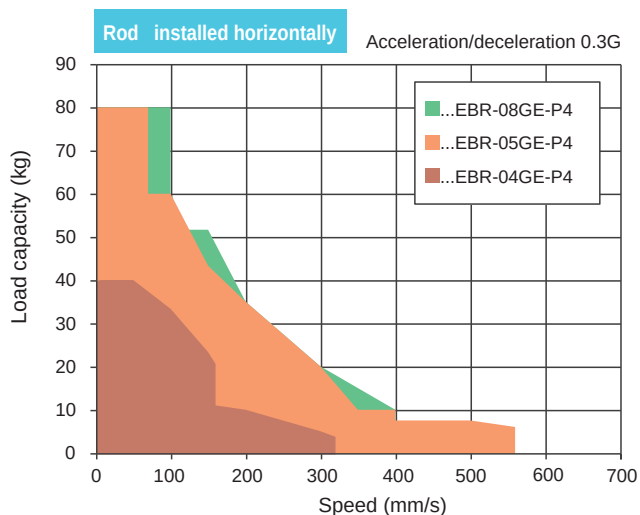

	Stroke (mm) and max. speed (mm/s)														Listed page	
	50 mm	100	150	200	250	300	350	400	450	500	550	600	650	700		
	160 mm/s															46
	320															
	160															50
	280															
	70															56
	240					210										
	400															
	560															
	70															60
	200															
	320															
	480															
	100														66	
	240															
	400															
	100														70	
	200															
	320															

EBR-P4
(With motor)

EBR-P4
(With motor)

ECC-A
(Controller)

Safety
precautions

*This data is at power supply voltage 24 VDC and acceleration/deceleration 0.3 G.
* The load capacity when wall mounted is the same as for horizontal installation.