

Auxiliary components

Bracket

**B Series**

Joiner

**J Series**



Structure/treatment and material restriction


	Structure/treatment	Model No.
P7 Series	Dust generation preventing	- <b>P70</b>

Dimensions and applications

**T bracket set**

● Model No.: B310-P70/B410-P70/B810-P70

● Examples

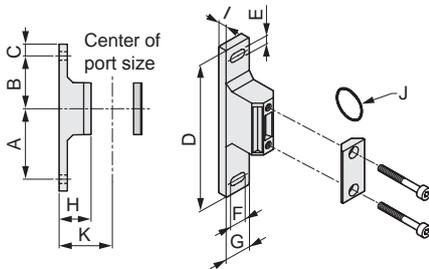

Note: Select B410 when using the 3000 Series and 4000 Series combined.


· Material: aluminum alloy die-cast coating processing

Model No.	Applicable model	A	B	C	D	E	F	G	H	I	J	K	Weight (kg)
B310-P70	2000 Series	60	45	10	125	7	14	22	27	7	JISB2401-P21	45	0.086
	3000 Series												
B410-P70	4000 Series	60	45	10	125	7	14	22	37	7	JISB2401-P21	55	0.094
B810-P70	6000 Series	70	50	15	150	9	14	27	37	8	AS568-127	65	0.169
	8000 Series												

**Joiner set**

● Model No.: C4000-J400-P70/C8000-J800-P70

● Examples

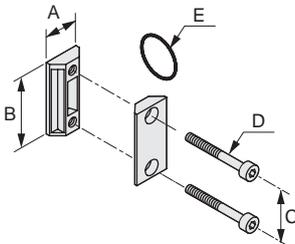

· Material: aluminum alloy die-cast coating processing

Model No.	Applicable model	A	B	C	D	E	Weight (kg)
C4000-J400-P70	2000 Series	21	44	32	M5	JIS B2401-P21	0.036
	3000 Series						
	4000 Series						
C8000-J800-P70	6000 Series	26	65	50	M6	AS568-127	0.094
	8000 Series						

SCPD3

SCM

SSD2

MDC2

SMG

LCM

LCR

LCG

LCX

STM

STG

STR2

MRL2

GRC

Cylinder Switch

MN3E  
MN4E

4GA/B

M4GA/B

MN4GA/B

F.R.(module unit)

Clean F.R

Precision R

Press gauge  
Diff. press gauge

Electro-pneumatic R

Speed controller

Auxiliary valve

Fitting/tube

Clean air unit

Pressure sensor

Flow rate sensor

Valve for air blow

Ending