


How to order mounting bolts

SSD2 - BOLT - d x L

Mounting bolts (Bolts are available in units of 4 bolts per set.)

How to read the list

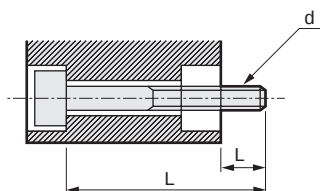

Material: Steel
Treatment: Black finish

d: Mounting bolt screw diameter
L: Mounting bolt length
L : Mating side screw-in available length
(Note) The mounting bolts will be displayed as d x L.

● SSD2, SSD2-K(ø12 to ø100)

Bore size	Stroke	L	d x L			
			SSD2	SSD2-L	SSD2-K	SSD2-KL
ø12 ø16	5	6.5	M3x25	M3x30	M3x30	M3x35
	10		x30	x35	x35	x40
	15		x35	x40	x40	x45
	20		x40	x45	x45	x50
	25		x45	x50	x50	x55
	30		x50	x55	x55	x60
ø20	5	6	M5x25	M5x35	M5x30	M5x40
	10		x30	x40	x35	x45
	15		x35	x45	x40	x50
	20		x40	x50	x45	x55
	25		x45	x55	x50	x60
	30		x50	x60	x55	x65
	35		x55	x65	x60	x70
	40		x60	x70	x65	x75
	45		x65	x75	x70	x80
	50		x70	x80	x75	x85
ø25	5	8	M5x30	M5x40	M5x35	M5x45
	10		x35	x45	x40	x50
	15		x40	x50	x45	x55
	20		x45	x55	x50	x60
	25		x50	x60	x55	x65
	30		x55	x65	x60	x70
	35		x60	x70	x65	x75
	40		x65	x75	x70	x80
	45		x70	x80	x75	x85
	50		x75	x85	x80	x90
ø32	5	7.5 (12.5)	M5x30	M5x40	M5x45	M5x55
	10		x35	x45	x50	x60
	15		x40	x50	x55	x65
	20		x45	x55	x60	x70
	25		x50	x60	x65	x75
	30		x55	x65	x70	x80
	35		x60	x70	x75	x85
	40		x65	x75	x80	x90
	45		x70	x80	x85	x95
	50		x75	x85	x90	x100
ø40	5	6	M5x35	M5x45	M5x45	M5x55
	10		x40	x50	x50	x60
	15		x45	x55	x55	x65
	20		x50	x60	x60	x70
	25		x55	x65	x65	x75
	30		x60	x70	x70	x80
	35		x65	x75	x75	x85
	40		x70	x80	x80	x90
	45		x75	x85	x85	x95
	50		x80	x90	x90	x100
ø50	5	11	x115	x115	x125	x125
	10		x120	x120	x130	x130
	15		x125	x125	x135	x135
	20		x130	x130	x140	x140
ø63	5	13	x135	x135	x145	x145
	10		x140	x140	x150	x150
	15		x145	x145	x155	x155
	20		x150	x150	x160	x160
ø80	5	17.5	x155	x155	x165	x165
	10		x160	x160	x170	x170
	15		x165	x165	x175	x175
	20		x170	x170	x180	x180
ø100	5	18	x175	x175	x185	x185
	10		x180	x180	x190	x190
	15		x185	x185	x195	x195
	20		x190	x190	x200	x200

Bore size	Stroke	L	d x L			
			SSD2	SSD2-L	SSD2-K	SSD2-KL
ø50	10	11	M6x45	M6x55	M6x55	M6x65
	15		x50	x60	x60	x70
	20		x55	x65	x65	x75
	25		x60	x70	x70	x80
	30		x65	x75	x75	x85
	35		x70	x80	x80	x90
	40		x75	x85	x85	x95
	45		x80	x90	x90	x100
	50		x85	x95	x95	x105
	75		x120	x120	x130	x130
ø63	100	13	x145	x145	x155	x155
	10		M8x50	M8x60	M8x60	M8x70
	15		x55	x65	x65	x75
	20		x60	x70	x70	x80
	25		x65	x75	x75	x85
	30		x70	x80	x80	x90
	35		x75	x85	x85	x95
	40		x80	x90	x90	x100
	45		x85	x95	x95	x105
	50		x90	x100	x100	x110
ø80	75	17.5	x125	x125	x135	x135
	100		x150	x150	x160	x160
	10		M10x60	M10x70	M10x70	M10x80
	15		x65	x75	x75	x85
	20		x70	x80	x80	x90
	25		x75	x85	x85	x95
	30		x80	x90	x90	x100
	35		x85	x95	x95	x105
	40		x90	x100	x100	x110
	45		x95	x105	x105	x115
ø100	50	18	x100	x110	x110	x120
	75		x135	x135	x145	x145
	100		x160	x160	x170	x170
	10		M10x70	M10x80	M10x80	M10x90
	15		x75	x85	x85	x95
	20		x80	x90	x90	x100
	25		x85	x95	x95	x105
	30		x90	x100	x100	x110
	35		x95	x105	x105	x115
	40		x100	x110	x110	x120
ø120	45	18	x105	x115	x115	x125
	50		x110	x120	x120	x130
	75		x145	x145	x155	x155
	100		x170	x170	x180	x180

* Values in () are for the high load (SSD2-K/KL).

● SSD2(ø125 to ø200)

Bore size	Stroke	L	dxL	
			SSD2	SSD2-L
ø125 ø140	10	20	M12x100	M12x100
	20		x110	x110
	30		x120	x120
	40		x130	x130
	50		x140	x140
	75		x165	x165
	100		x190	x190
ø160	10	24.2	M14x110	M14x110
	20		x120	x120
	30		x130	x130
	40		x140	x140
	50		x150	x150
	75		x175	x175
	100		x200	x200
ø180	10	36	M18x125	M18x125
	20		x135	x135
	30		x145	x145
	40		x155	x155
	50		x165	x165
	75		x190	x190
	100		x215	x215
ø200	10	39	M18x135	M18x135
	20		x145	x145
	30		x155	x155
	40		x165	x165
	50		x175	x175
	75		x200	x200
	100		x225	x225

● SSD2-X, SSD2-Y, SSD2-M

Bore size	Stroke	L	dxL			
			SSD2-X,Y	SSD2-XL,YL	SSD2-M	SSD2-ML
ø12 ø16	5	6.5	M3x25	M3x30	M3x30	M3x35
	10		x30	x35	x35	x40
	15				x40	x45
	20				x45	x50
	25				x50	x55
	30				x55	x60
	30				x55	x60
ø20	5	6	M5x25	M5x35	M5x30	M5x40
	10		x30	x40	x35	x45
	15				x40	x50
	20				x45	x55
	25				x50	x60
	30				x55	x65
	35				x60	x70
	40				x65	x75
	45				x70	x80
	50				x75	x85
ø25	5	8	M5x30	M5x40	M5x35	M5x45
	10		x35	x45	x40	x50
	15				x45	x55
	20				x50	x60
	25				x55	x65
	30				x60	x70
	35				x65	x75
	40				x70	x80
	45				x75	x85
	50				x80	x90
ø32	5	8.5	M5x30	M5x40	M5x40	M5x50
	10		x35	x45	x45	x55
	15				x50	x60
	20				x55	x65
	25				x60	x70
	30				x65	x75
	35				x70	x80
	40				x75	x85
	45				x80	x90
	50				x85	x95
	75				x120	x120
	100				x145	x145
ø40	5	6	M5x35	M5x45	M5x35	M5x45
	10		x40	x50	x40	x50
	15				x45	x55
	20				x50	x60
	25				x55	x65
	30				x60	x70
	35				x65	x75
	40				x70	x80
	45				x75	x85
	50				x80	x90
	75				x115	x115
	100				x140	x140
ø50	10	11	M6x45	M6x55	M6x45	M6x55
	15				x50	x60
	20				x55	x65
	25				x60	x70
	30				x65	x75
	35				x70	x80
	40				x75	x85
	45				x80	x90
	50				x85	x95
	75				x120	x120
	100				x145	x145
ø63	10	13			M8x50	M8x60
	15				x55	x65
	20				x60	x70
	25				x65	x75
	30				x70	x80
	35				x75	x85
	40				x80	x90
	45				x85	x95
	50				x90	x100
	75				x125	x125
	100				x150	x150

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/
COVP/IN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/
MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd
Contr

Ending

SSD2 Series

● SSD2-D, SSD2-Q

SCP*3	● SSD2-D, SSD2-Q								
	Bore size	Stroke	L	dxL					
				SSD2-D	SSD2-DL	SSD2-Q(L)-R		SSD2-Q(L)-H	
CMK2	ø12 ø16	5	6.5	M3x30	M3x35				
CMA2		10		x35	x40				
		15		x40	x45				
SCM		20		x45	x50				
		25		x50	x55				
		30		x55	x60				
SCG	ø20	5	9.5 (11.5) [12]	M5x35	M5x45				
SCA2		10		x40	x50			M5x70	M5x80
		15		x45	x55	x75	x85		
SCS2		20		x50	x60	x80	x90		
		25		x55	x65	x85	x100		
CKV2		30		x60	x70				
		35		x65	x75				
CAV2/ COVPIN2		40		x70	x80				
		45		x75	x85				
SSD2		50		x80	x90	x130	x130		
		75				x155	x155		
		100				x180	x180		
SSG		ø25		5	11.5 (10.5) [9]	M5x40	M5x50		
SSD				10		x45	x55		
	15		x50	x60		x75	x80		
CAT	20		x55	x65		x80	x85		
	25		x60	x70		x85	x90		
MDC2	30		x65	x75					
	35		x70	x80					
MVC	40		x75	x85					
	45		x80	x90					
SMG	50		x85	x95		x120	x120		
	75					x145	x145		
	100					x170	x170		
MSD/ MSDG	ø32	5	10 (12.5) [15]	M5x40	M5x50				
FC*		10		x45	x55			M5x75	M5x85
		15		x50	x60	x80	x90		
STK		20		x55	x65	x85	x95		
		25		x60	x70	x90	x100		
SRL3		30		x65	x75				
		35		x70	x80				
SRG3		40		x75	x85				
		45		x80	x90				
SRM3		50		x85	x95	x115	x125		
		75		x120	x120	x140	x150		
		100		x145	x145	x165	x175		
MRL2	ø40	5	10.5 (11.5) [11]	M5x50	M5x60				
MRG2		10		x55	x65			M5x80	M5x90
		15		x60	x70	x85	x95		
SM-25		20		x65	x75	x90	x100		
		25		x70	x80	x95	x105		
ShkAbs		30		x75	x85				
		35		x80	x90				
FJ		40		x85	x95				
		45		x90	x100				
FK		50		x95	x105	x120	x130		
		75		x130	x130	x145	x155		
Ending		100		x155	x155	x170	x175		

Bore size	Stroke	L	dxL			
			SSD2-D	SSD2-DL	SSD2-Q(L)-R	SSD2-Q(L)-H
ø63	10	12 (18) [17]	M8x50	M8x60	M8x90	M8x95
	15		x55	x65	x95	x100
	20		x60	x70	x100	x105
	25		x65	x75	x105	x110
	30		x70	x80		
	35		x75	x85		
	40		x80	x90		
	45		x85	x95		
	50		x90	x100	x130	x135
	75		x125	x125	x155	x160
100	x150	x150	x180	x185		
ø80	10	16 (12.5) [15]	M10x65	M10x75		
	15		x70	x80		
	20		x75	x85		
	25		x80	x90		
	30		x85	x95		
	35		x90	x100		
	40		x95	x105		
	45		x100	x110		
	50		x105	x115	x155	x150
	75		x140	x140	x180	x180
100	x165	x165	x205	x205		
ø100	10	16.5 (13) [15.5]	M10x75	M10x85		
	15		x80	x90		
	20		x85	x95		
	25		x90	x100		
	30		x95	x105		
	35		x100	x110		
	40		x105	x115		
	45		x110	x120		
	50		x115	x125	x165	x160
	75		x150	x150	x190	x190
100	x175	x175	x215	x215		
ø125 ø140	10	20	M12x100	M12x100		
	20		x110	x110		
	30		x120	x120		
	40		x130	x130		
	50		x140	x140		
	75		x165	x165		
	100		x190	x190		
ø160	10	24.2	M14x110	M14x110		
	20		x120	x120		
	30		x130	x130		
	40		x140	x140		
	50		x150	x150		
	75		x175	x175		
	100		x200	x200		
ø180	10	36	M18x125	M18x125		
	20		x135	x135		
	30		x145	x145		
	40		x155	x155		
	50		x165	x165		
	75		x190	x190		
	100		x215	x215		
ø200	10	39	M18x135	M18x135		
	20		x145	x145		
	30		x155	x155		
	40		x165	x165		
	50		x175	x175		
	75		x200	x200		
	100		x225	x225		

* Values in () are for SSD2-Q(L)-R.

* Values in [] are for SSD2-Q(L)-H.

● SSD2-G1, 4

Bore size	Stroke	L	dxL	
			SSD2-G1, 4	SSD2-G1, 4L
ø32	5	7.5	M5x30	M5x40
	10		x35	x45
	15		x40	x50
	20		x45	x55
	25		x50	x60
	30		x55	x65
	35		x60	x70
	40		x65	x75
	45		x70	x80
	50		x75	x85
	75		x110	x120
	100		x135	x145
ø40	5	6	M5x35	M5x45
	10		x40	x50
	15		x45	x55
	20		x50	x60
	25		x55	x65
	30		x60	x70
	35		x65	x75
	40		x70	x80
	45		x75	x85
	50		x80	x90
	75		x115	x125
	100		x140	x150
ø50	10	11	M6x45	M6x55
	15		x50	x60
	20		x55	x65
	25		x60	x70
	30		x65	x75
	35		x70	x80
	40		x75	x85
	45		x80	x90
	50		x85	x95
	75		x120	x130
	100		x145	x155
ø63	10	13	M8x50	M8x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
	75		x125	x135
	100		x150	x160
ø80	10	17.5	M10x60	M10x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
	75		x135	x145
	100		x160	x170
ø100	10	18	M10x70	M10x80
	15		x75	x85
	20		x80	x90
	25		x85	x95
	30		x90	x100
	35		x95	x105
	40		x100	x110
	45		x105	x115
	50		x110	x120
	75		x145	x155
	100		x170	x180

● SSD2-G5

Bore size	Stroke	L	dxL	
			SSD2-G5	SSD2-G5L
ø32	5	7.5	M5x40	M5x50
	10		x45	x55
	15		x50	x60
	20		x55	x65
	25		x60	x70
	30		x65	x75
	35		x70	x80
	40		x75	x85
	45		x80	x90
	50		x85	x95
	75		x115	x130
	100		x140	x155
ø40	5	6	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
	75		x125	x135
	100		x150	x160
ø50	10	11	M6x55	M6x65
	15		x60	x70
	20		x65	x75
	25		x70	x80
	30		x75	x85
	35		x80	x90
	40		x85	x95
	45		x90	x100
	50		x95	x105
	75		x130	x140
	100		x155	x165
ø63	10	13	M8x60	M8x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
	75		x135	x145
	100		x160	x170
ø80	10	17.5	M10x70	M10x80
	15		x75	x85
	20		x80	x90
	25		x85	x95
	30		x90	x100
	35		x95	x105
	40		x100	x110
	45		x105	x115
	50		x110	x120
	75		x145	x155
	100		x170	x180
ø100	10	18	M10x80	M10x90
	15		x85	x95
	20		x90	x100
	25		x95	x105
	30		x100	x110
	35		x105	x115
	40		x110	x120
	45		x115	x125
	50		x120	x130
	75		x155	x165
	100		x180	x190

SCP*3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2/ COVP/IN2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD/ MSDG
FC*
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
ShkAbs
FJ
FK
Spd Contr
Ending

SSD2 Series

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/
COVPIN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/
MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd
Contr

Ending

● SSD2-G, G2, 3

Bore size	Stroke	L	dxL	
			SSD2-G, G2, 3	SSD2-G, G2, 3L
ø20	5	6	M5x25	M5x35
	10		x35	x45
	15		x40	x50
	20		x45	x55
	25		x50	x60
	30		x55	x65
	35		x60	x70
	40		x65	x75
	45		x70	x80
	50		x75	x85
	ø25		5	8
10		x35	x45	
15		x40	x50	
20		x45	x55	
25		x50	x60	
30		x55	x65	
35		x60	x70	
40		x65	x75	
45		x70	x80	
50		x75	x85	
ø32		5	7.5	
	10	x35		x45
	15	x40		x50
	20	x45		x55
	25	x50		x60
	30	x55		x65
	35	x60		x70
	40	x65		x75
	45	x70		x80
	50	x75		x85
	75	x105		x120
100	x130	x145		
ø40	5	6	M5x35	M5x45
	10		x40	x50
	15		x45	x55
	20		x50	x60
	25		x55	x65
	30		x60	x70
	35		x65	x75
	40		x70	x80
	45		x75	x85
	50		x80	x90
	75		x115	x125
100	x140	x150		
ø50	10	11	M6x45	M6x55
	15		x50	x60
	20		x55	x65
	25		x60	x70
	30		x65	x75
	35		x70	x80
	40		x75	x85
	45		x80	x90
	50		x85	x95
	75		x120	x130
	100		x145	x155
ø63	10	13	M8x50	M8x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
	75		x125	x135
	100		x150	x160
ø80	10	17.5	M10x60	M10x70
	15		x65	x75
	20		x70	x80
	25		x75	x85

ø80

30

17.5

x80

x90

35

x85

x95

40

x90

x100

45

x95

x105

50

x100

x110

75

x135

x145

100

x160

x170

ø100

10

18

M10x70

M10x80

15

x75

x85

20

x80

x90

25

x85

x95

30

x90

x100

35

x95

x105

40

x100

x110

45

x105

x115

50

x110

x120

75

x145

x155

100

x170

x180

● SSD2-T1L

Bore size	Stroke	L	dxL
			SSD2-T1L
ø32	5	7.5	M5x40
	10		x45
	15		x50
	20		x55
	25		x60
	30		x65
	35		x70
	40		x75
	45		x80
	50		x85
	75		x120
100	x145		
ø40	5	6	M5x45
	10		x50
	15		x55
	20		x60
	25		x65
	30		x70
	35		x75
	40		x80
	45		x85
	50		x90
	75		x125
100	x150		
ø50	10	11	M6x55
	15		x60
	20		x65
	25		x70
	30		x75
	35		x80
	40		x85
	45		x90
	50		x95
	75		x130
	100		x155
ø63	10	13	M8x60
	15		x65
	20		x70
	25		x75
	30		x80
	35		x85
	40		x90
	45		x95
	50		x100
	75		x135
	100		x160

● SSD2-K-*C

Bore size	Stroke	L	dxL	
			SSD2-K-*C	SSD2-KL-*C
ø20	5	6	M5x30	M5x40
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø25	5	8	M5x35	M5x45
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø32	5	7.5	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø40	5	6	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø50	5	11	M6x55	M6x65
	10		x60	x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
ø63	10	13	M8x60	M8x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
	75		x135	x145
ø80	10	17.5	M10x70	M10x80
	15		x75	x85
	20		x80	x90
	25		x85	x95
	30		x90	x100
	35		x95	x105
	40		x100	x110
	45		x105	x115
	50		x110	x120
	75		x145	x155
ø100	10	18	M10x80	M10x90
	15		x85	x95
	20		x90	x100
	25		x95	x105
	30		x100	x110
	35		x105	x115
	40		x110	x120
	45		x115	x125
	50		x120	x130
	75		x155	x165
ø100	100		x180	x190

● SSD2-KU

Bore size	Stroke	L	dxL	
			SSD2-KU	SSD2-KUL
ø20	5	6	M5x30	M5x40
	10		x35	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø25	5	8	M5x35	M5x45
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø32	5	7.5	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø40	5	6	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
ø50	5	11	M6x55	M6x65
	10		x60	x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
ø63	10	13	M8x60	M8x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
	75		x135	x145
ø80	10	17.5	M10x70	M10x80
	15		x75	x85
	20		x80	x90
	25		x85	x95
	30		x90	x100
	35		x95	x105
	40		x100	x110
	45		x105	x115
	50		x110	x120
	75		x145	x155
ø100	10	18	M10x80	M10x90
	15		x85	x95
	20		x90	x100
	25		x95	x105
	30		x100	x110
	35		x105	x115
	40		x110	x120
	45		x115	x125
	50		x120	x130
	75		x155	x165
ø100	100		x180	x190

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/
COVP/IN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/
MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd
Contr

Ending

SSD2 Series

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/COVPIN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd Contr

Ending

● SSD2-L4

Bore size	Stroke	L	d×L	
			SSD2-KU	SSD2-KUL
ø40	5	6	M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
	75		x125	x135
	100		x150	x160
ø50	10	11	M6x55	M6x65
	15		x60	x70
	20		x65	x75
	25		x70	x80
	30		x75	x85
	35		x80	x90
	40		x85	x95
	45		x90	x100
	50		x95	x105
	75		x130	x140
	100		x155	x165
	10		M8x60	M8x70
ø63	15	13	x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
	50		x100	x110
	75		x135	x145
	100		x160	x170
ø80	10	17.5	M10x70	M10x80
	15		x75	x85
	20		x80	x90
	25		x85	x95
	30		x90	x100
	35		x95	x105
	40		x100	x110
	45		x105	x115
	50		x110	x120
	75		x145	x155
	100		x170	x180
ø100	10	18	M10x80	M10x90
	15		x85	x95
	20		x90	x100
	25		x95	x105
	30		x100	x110
	35		x105	x115
	40		x110	x120
	45		x115	x125
	50		x120	x130
	75		x155	x165
	100		x180	x190

● SSD2-P7*/P5*

Bore size	Stroke	L	d×L	
			SSD2-K-*C	SSD2-KL-*C
ø12	5	6.5	M5x35	M5x45
	10		x45	x60
	15		x50	x65
	20		x55	x70
	25		x60	x75
	30		x65	x80
ø16	5	6.5	M5x40	M5x50
	10		x45	x60
	15		x50	x65
	20		x55	x70
	25		x60	x75
	30		x65	x80
ø20	5	6	M5x35	M5x45
	10		x45	x60
	15		x50	x65
	20		x55	x70
	25		x60	x75

ø20	30	6	M5x65	M5x80
	35		x70	x85
	40		x75	x90
	45		x80	x95
	50		x85	x100
ø25	5	8	M5x40	M5x50
	10		x45	x60
	15		x50	x65
	20		x55	x70
	25		x60	x75
	30		x65	x80
	35		x70	x85
	40		x75	x90
	45		x80	x95
ø32	50	7.5	x85	x100
	5		M5x40	M5x55
	10		x45	x60
	15		x50	x65
	20		x55	x70
	25		x60	x75
	30		x65	x80
	35		x70	x85
	40		x75	x90
	45		x80	x95
	50		x85	x100
	75		x120	x135
ø40	100	6	x145	x160
	5		M5x45	M5x55
	10		x50	x60
	15		x55	x65
	20		x60	x70
	25		x65	x75
	30		x70	x80
	35		x75	x85
	40		x80	x90
	45		x85	x95
	50		x90	x100
	75		x125	x135
ø50	100	11	x150	x160
	10		M6x55	M6x65
	15		x60	x70
	20		x65	x75
	25		x70	x80
	30		x75	x85
	35		x80	x90
	40		x85	x95
	45		x90	x100
	50		x95	x105
ø63	75	13	x130	x140
	100		x155	x165
	10		M8x60	M8x70
	15		x65	x75
	20		x70	x80
	25		x75	x85
	30		x80	x90
	35		x85	x95
	40		x90	x100
	45		x95	x105
ø80	50	17.5	x100	x110
	75		x135	x145
	100		x160	x170
	10		M10x75	M10x85
	15		x80	x90
	20		x85	x95
	25		x90	x100
	30		x95	x105
	35		x100	x110
	40		x105	x115
ø100	45	18	x110	x120
	50		x115	x125
	75		x150	x160
	100		x175	x185
	10		M10x85	M10x95
	15		x90	x100
	20		x95	x105
	25		x100	x110
	30		x105	x115
	35		x110	x120
	40		x115	x125
	45		x120	x130
	50		x125	x135
	75		x160	x170
	100		x185	x195

1056

CKD