

SCP*3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2/
COVPIN2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD/
MSDG
FC*
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
ShkAbs
FJ
FK
Spd
Contr
Ending

Even easier to use with added variations.



Fine speed (SMG-F Series)

Smooth, low speed operation from 1 mm/sec is realized.



Rotation-stop (SMG-M Series)



Clean-room specifications (SMG-P7*/P5* Series)

Dust generation in clean rooms is prevented (P7)
and copper, silicon, and halogen materials are not used (P5)

Lightweight and space saving


Space saving and lightweight with integration of mount block.

Max.

33%
lighter in weight
(vs. conventional)

Max.


23%
space saving
(vs. conventional)

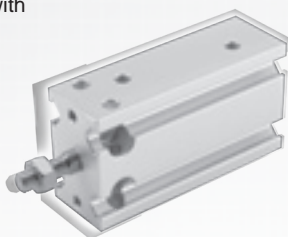

Simple shape for flexible mounting


Integration of mount block enables flexible selection from five direct mounting surfaces as standard.

Direct mounting
from 5 faces

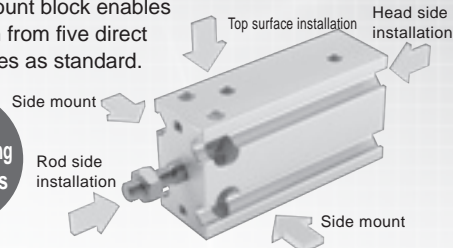

Detection switch fits in completely

Detection switch fits into the body with barely any protrusion.

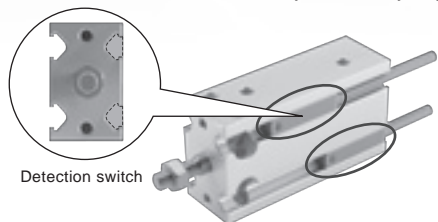

Detection switch

Sleek and
flat

Easy maintenance

A new mounting method has been developed for easy maintenance.

Easy
maintenance

Rod packing

