


Configurations table

Switch

● Switch body + mounting bracket set (*1)

SRL3 - M0H*

Switch model No.
(Item ㊦ on page 1576)

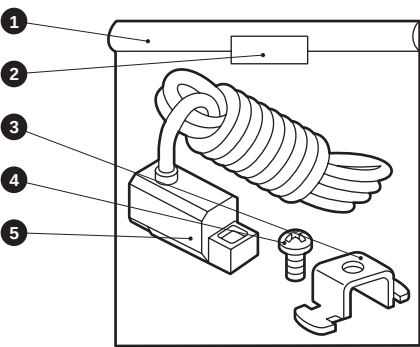


No.	Part name	Qty.
1	Plastic bag	1
2	Label	1
3	Switch mounting bracket	1
4	Cross-recessed pan head machine screw	1
5	Switch	1

● Switch body only

SW - M0H*

Switch model No.
(Item ㊦ on page 1576)

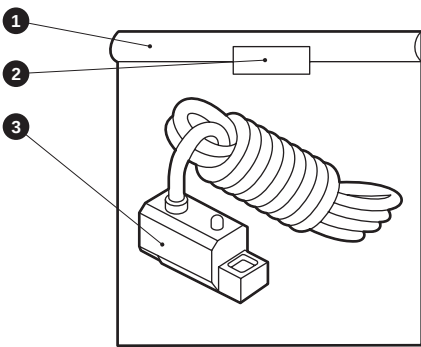


No.	Part name	Qty.
1	Plastic bag	1
2	Label	1
3	Switch	1

Switch


● Mounting bracket only

SRL3 - M

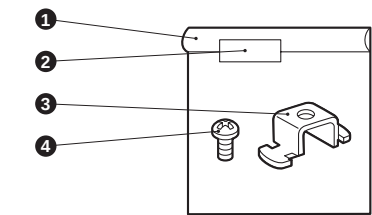

● Mounting bracket only


SRL3 - T

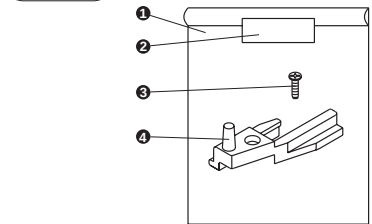

No.	Part name	Qty.
1	Plastic bag	1
2	Label	1
3	Switch mounting bracket	1
4	Cross-recessed pan head machine screw	1

● Lead wire holder

SRL3 - MH

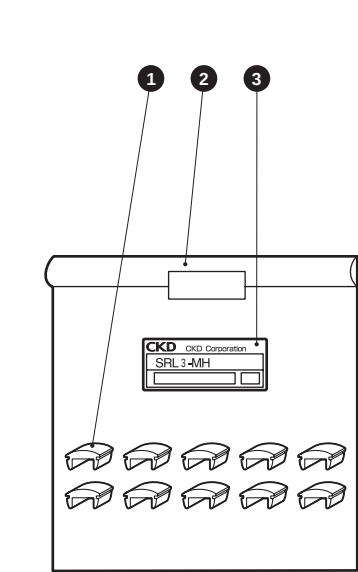

No.	Part name	Qty.
1	Lead wire holder	10
2	Plastic bag	1
3	Package label (S)	1



Note: Packing details may differ depending on the product size.

Repair parts

SRL3 - 40 K - 200

Bore size
(Item (B) on page 1576)

Stroke
(Item (E) on page 1576)

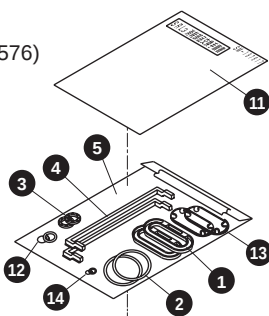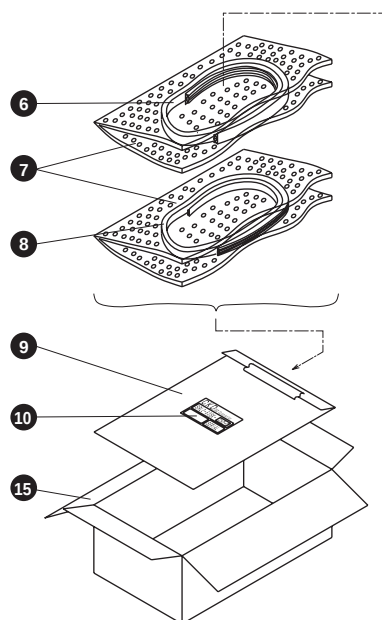

No.	Part name	Qty.
1	Piston packing	2
2	O-ring P	2
3	Cushion packing	2
4	Dust wiper	2
5	Plastic bag	1
6	Seal belt	1
7	Bubble wrapping	1
8	Dust-proof belt	1
9	Plastic bag	1
10	Package label (L)	1
11	Repair parts replacement procedures	1
12	Special O-ring	2
13	Cushion ring gasket	2
14	Needle gasket	2
15	Carton	1

*1: Cushion ring gaskets are not included in $\phi 12$ to $\phi 40$.

*2: Four gaskets are added with $\phi 80$ to $\phi 100$.


Mounting bracket

SRL3 - LB - 40


Mounting
(Item (A) on page 1576)

Bore size
(Item (B) on page 1576)

Bracket x 2 + mounting bolt x 4

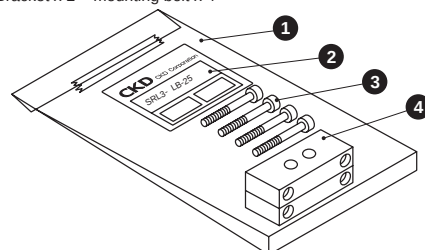

No.	Part name	Qty.
1	Plastic bag	1
2	Package label (S)	1
3	Hexagon socket head cap screw	4
4	Foot bracket (A)	2

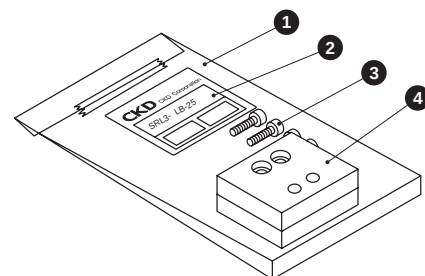


No.	Part name	Qty.
1	Plastic bag	1
2	Package label (S)	1
3	Hexagon socket head cap screw	4
4	Foot bracket (B)	2

Full stroke adjusting bracket kit

SRL3 - 40 - A1 1 set



Bore size
(Item (B) on page 1576)

[$\phi 12$ to $\phi 25$]

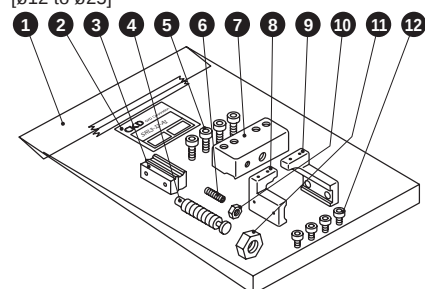



No.	Part name	Qty.
1	Plastic bag	1
2	Package label (S)	1
3	Flat nut	2
4	Shock absorber	1
5	Hexagon socket head cap screw	4
6	Hexagon socket set screw	1
7	Plate	1
8	Adaptor (R)	1
9	Adaptor (L)	1
10	Stopper bolt fixing nut	1
11	Shock absorber fixing nut	1
12	Hexagon socket head cap screw	4

[$\phi 32$ to $\phi 63$]

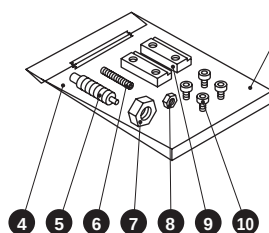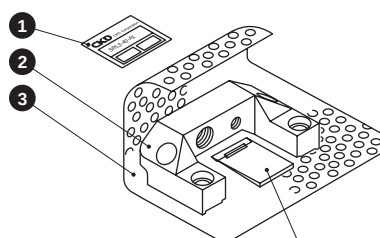

No.	Product name	Qty.
1	Package label (S)	1
2	Adaptor	1
3	Bubble wrapping	1
4	Plastic bag	1
5	Shock absorber	1
6	Hexagon socket set screw	1

[$\phi 80/\phi 100$]

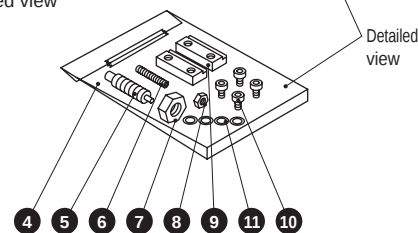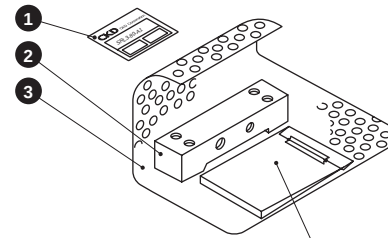

No.	Product name	Qty.
7	Hexagon nut	1
8	Hexagon nut	1
9	Adaptor nut	2
10	Hexagon socket head cap screw	4
11	Disc spring	4


Note: Packing details may differ depending on the product size.

SCP*3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2/ COVPIN2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD/ MSDG
FC*
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
ShkAbs
FJ
FK
Spd Contr
Ending

Floating fitting set

SRL3 - 40 - Y

Bore size
(Item (B) on page 1576)

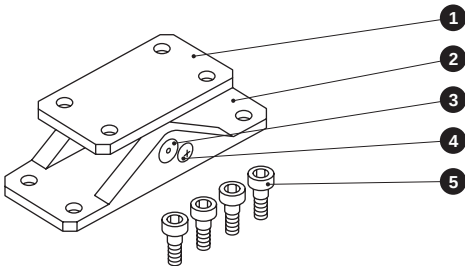

No.	Part name	Qty.
1	Mount	1
2	Mount base	1
3	Pin	1
4	Pan head machine screw with spring washer	1
5	Mounting bolt	4


Note: Packing details may differ depending on the product size.

Intermediate support bracket

● For 00/LB

SRL3 - 40 - L 2 pcs./set

Bore size
(Item (B) on page 1576)

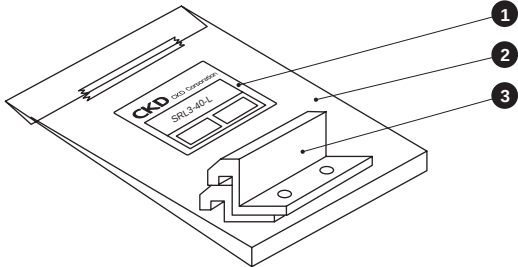


No.	Part name	Qty.
1	Package label (S)	1
2	Plastic bag	1
3	Intermediate support bracket	2

● For LB1

SRL3 - 32 - N 2 pcs./set

Bore size
(Item (B) on page 1576)

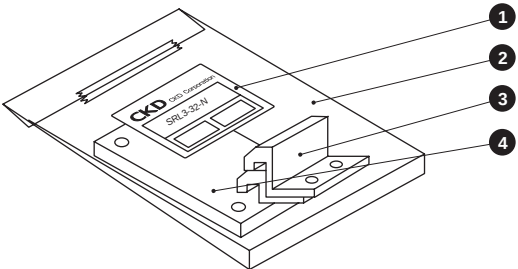

No.	Part name	Qty.
1	Package label (S)	1
2	Plastic bag	1
3	Intermediate support bracket	2
4	Plate	1

Kit weight list

Floating fitting

Kit No.	Weight (g)
SRL3-12-Y	86
SRL3-16-Y	86
SRL3-20-Y	189
SRL3-25-Y	188
SRL3-32-Y	572
SRL3-40-Y	571
SRL3-50-Y	1194
SRL3-63-Y	1188
SRL3-80-Y	2638
SRL3-100-Y	4115

Intermediate support bracket

● For 00/LB

Kit No.	Weight (g)
SRL3-12-L	12
SRL3-16-L	14
SRL3-20-L	21
SRL3-25-L	35
SRL3-32-L	35
SRL3-40-L	70
SRL3-50-L	87
SRL3-63-L	199
SRL3-80-L	337
SRL3-100-L	337

● For LB1

Kit No.	Weight (g)
SRL3-12-N	40
SRL3-16-N	49
SRL3-20-N	81
SRL3-25-N	123
SRL3-32-N	136

Discrete shock absorber

Kit No.	Weight (g)
SRL3-12-NCK	14
SRL3-16-NCK	14
SRL3-20-NCK	23
SRL3-25-NCK	45
SRL3-32-NCK	77
SRL3-40-NCK	212
SRL3-50-NCK	330
SRL3-63-NCK	330
SRL3-80-NCK	475
SRL3-100-NCK	475

Thin floating fitting

Kit No.	Weight (g)
SRL3-12-Y1	139
SRL3-16-Y1	157
SRL3-20-Y1	291
SRL3-25-Y1	403
SRL3-32-Y1	732
SRL3-40-Y1	879
SRL3-50-Y1	1590
SRL3-63-Y1	2057

Mounting bracket

● For LB

Kit No.	Weight (g)
SRL3-LB-12	13
SRL3-LB-16	15
SRL3-LB-20	28
SRL3-LB-25	88
SRL3-LB-32	103
SRL3-LB-40	152
SRL3-LB-50	272
SRL3-LB-63	448
SRL3-LB-80	610
SRL3-LB-100	1014

● For LB1

Kit No.	Weight (g)
SRL3-LB1-12	25
SRL3-LB1-16	27
SRL3-LB1-20	58
SRL3-LB1-25	123
SRL3-LB1-32	161

Height adjustment plate

Kit No.	Weight (g)
SRL3-12-U	52
SRL3-16-U	47
SRL3-20-U	75
SRL3-25-U	173
SRL3-32-U	225
SRL3-40-U	352
SRL3-50-U	620
SRL3-63-U	873
SRL3-80-U	1396
SRL3-100-U	2070

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/
COVP/IN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/
MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd
Contr

Ending

SCP*3

CMK2

CMA2

SCM

SCG

SCA2

SCS2

CKV2

CAV2/
COVPIN2

SSD2

SSG

SSD

CAT

MDC2

MVC

SMG

MSD/
MSDG

FC*

STK

SRL3

SRG3

SRM3

SRT3

MRL2

MRG2

SM-25

ShkAbs

FJ

FK

Spd
Contr

Ending

Kit weight list

Switch related parts

● Mounting bracket only

Kit No.	Weight (g)
SRL3-M	1
SRL3-T	5

Note: In the case of the mounting bracket + switch, add the switch weight.

● Lead wire holder

Kit No.	Weight (g)
SRL3-MH	3

Repair parts

● SRL3 Series

Kit No.	Weight (g)
SRL3-12K-□	7 + 5 x stroke/100
SRL3-16K-□	8 + 5 x stroke/100
SRL3-20K-□	10 + 5 x stroke/100
SRL3-25K-□	24 + 10 x stroke/100
SRL3-32K-□	31 + 10 x stroke/100
SRL3-40K-□	54 + 18 x stroke/100
SRL3-50K-□	66 + 18 x stroke/100
SRL3-63K-□	91 + 18 x stroke/100
SRL3-80K-□	248 + 42 x stroke/100
SRL3-100K-□	268 + 42 x stroke/100

● SRL3-G Series

Kit No.	Weight (g)
SRL3-G-12K-□	7 + 5 x stroke/100
SRL3-G-16K-□	9 + 5 x stroke/100
SRL3-G-20K-□	11 + 5 x stroke/100
SRL3-G-25K-□	28 + 10 x stroke/100
SRL3-G-32K-□	36 + 10 x stroke/100
SRL3-G-40K-□	59 + 18 x stroke/100
SRL3-G-50K-□	78 + 18 x stroke/100
SRL3-G-63K-□	104 + 18 x stroke/100
SRL3-G-80K-□	296 + 42 x stroke/100
SRL3-G-100K-□	319 + 42 x stroke/100

● SRL3-Q Series

Kit No.	Weight (g)
SRL3-Q-12K-□	7 + 5 x stroke/100
SRL3-Q-16K-□	8 + 5 x stroke/100
SRL3-Q-20K-□	10 + 5 x stroke/100
SRL3-Q-25K-□	25 + 10 x stroke/100
SRL3-Q-32K-□	31 + 10 x stroke/100
SRL3-Q-40K-□	54 + 18 x stroke/100
SRL3-Q-50K-□	68 + 18 x stroke/100
SRL3-Q-63K-□	92 + 18 x stroke/100
SRL3-Q-80K-□	250 + 42 x stroke/100
SRL3-Q-100K-□	270 + 42 x stroke/100

● SRL3-GQ Series

Kit No.	Weight (g)
SRL3-GQ-12K-□	8 + 5 x stroke/100
SRL3-GQ-16K-□	9 + 5 x stroke/100
SRL3-GQ-20K-□	11 + 5 x stroke/100
SRL3-GQ-25K-□	29 + 10 x stroke/100
SRL3-GQ-32K-□	37 + 10 x stroke/100
SRL3-GQ-40K-□	60 + 18 x stroke/100
SRL3-GQ-50K-□	80 + 18 x stroke/100
SRL3-GQ-63K-□	105 + 18 x stroke/100
SRL3-GQ-80K-□	298 + 42 x stroke/100
SRL3-GQ-100K-□	322 + 42 x stroke/100

Full stroke adjusting kit

Kit No.	Weight (g)
SRL3-12-A1	110
SRL3-16-A1	114
SRL3-20-A1	187
SRL3-25-A1	375
SRL3-32-A1	644
SRL3-40-A1	1032
SRL3-50-A1	2128
SRL3-63-A1	2454
SRL3-80-A1	3108
SRL3-100-A1	3422