

Contact protecting circuit box

SKAC/SKDC



Specifications

Item	For AC circuit		For DC circuit
	SKAC		SKDC
Load voltage	100/110 VAC	200/220 VAC	24 VDC
Load current	20 mA or less	10 mA or less	50 mA or less
Lead wire length	1 m (oil resistant vinyl cabtyre cable 2-conductor 0.2 mm <sup>2</sup> )		
Shock resistance	980 m/s <sup>2</sup>		
Insulation resistance	100 MΩ or more at 500 VDC megger		
Withstand voltage	No failure after 1 minute of 1,500 VAC application		
Ambient temperature	-10 (14°F) to +60°C (140°F)		
Degree of protection	IEC Standards IP67, JIS C0920 (water-tight), oil resistance		


How to order

SW - SKAC


Code	Description
SKAC	Circuit AC
SKDC	Circuit DC

Dimensions

● SKAC/SKDC Series

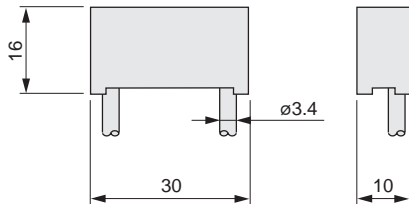

Internal circuit diagram

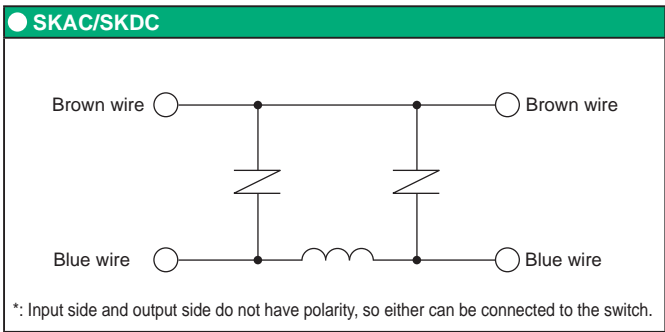

Note: SKAC is for AC circuit only and SKDC is for DC circuit only.

Cylinder switch