


Series variation

Brake cylinder ULKP/ULK Series

LCM
LCR
LCG
LCW
LCX
STM
STG
STS/STL
STR2
UCA2
ULK*
JSK/M2
JSG
JSC3/JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3*
NHS
HRL
LN
Hand
Chuk
MecHnd/Chuk
ShkAbs
FJ
FK
SpdContr
Ending

Variation	Model No. JIS symbol	Bore size (mm)	Standard stroke (mm)												Min. stroke (mm)	
			15	25	30	45	50	60	75	100	150	200	250	300		
Discontinued model			15	25	30	45	50	60	75	100	150	200	250	300		
Double acting	ULKP 	ø16	●		●	●		●							5	
Double acting	ULK 	ø20/ø25/ ø32/ø40		●			●		●	●	●	●	●	●	5	
Double acting/with valve	ULK-V	ø20/ø25/ ø32/ø40		●			●		●	●	●	●	●	●	5	

Product introduction

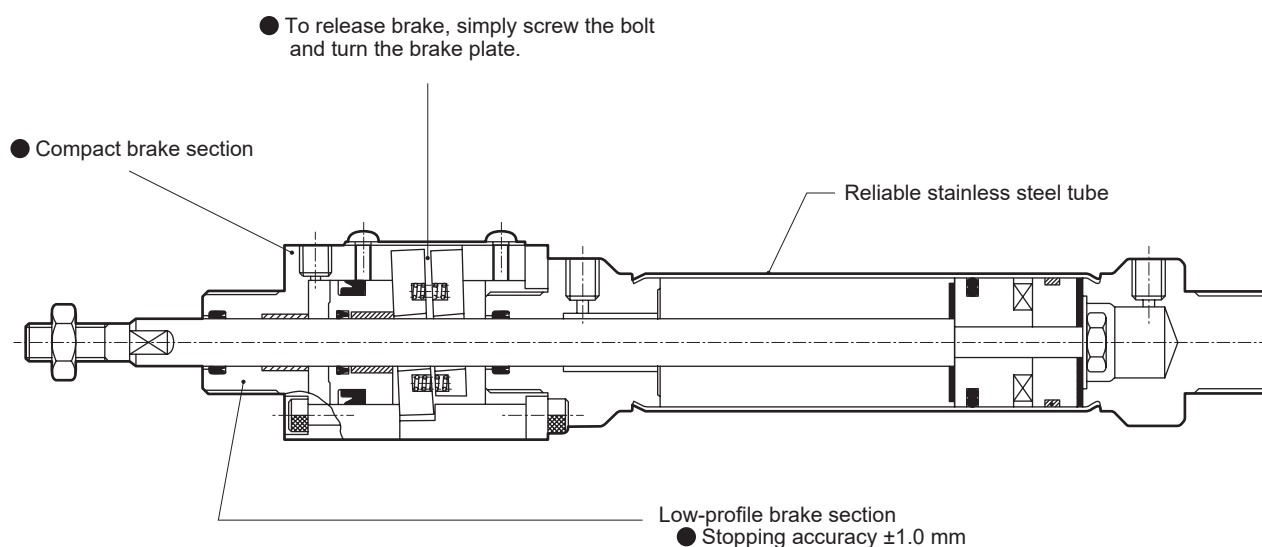

Space-saving model.

● : Standard, ◎ : Option, ○ : Made to order, ■ : Not available

Discontinued model	Max. stroke (mm)	Custom stroke (per mm)	Mounting										Option										Switch	Page
			Basic	Axial foot	Rod side axial foot	Rod side flange	Eye bracket	Clevis bracket	Eye bracket integrated	Eye bracket bush pressfit	Rod side trunnion	Head side trunnion	Bellows (100°C)	Bellows (250°C)	Piston rod material change	Boss cutoff	Rod eye	Rod clevis	Eye bracket	Clevis bracket				
	00	LB	LS	FA	CA	CB	CC	CC1	TA	TB	J	L	M	V	I	Y	B1	B2						
	260	1	●		●	●		●								◎	◎	◎	◎	◎	674			
	700	1	●	●		●	●		●	●	●	●	◎	◎	◎	◎	◎	◎		◎	◎	680		
	700	1	●	●		●	●		●	●	●	●	◎	◎	◎	◎	◎	◎		◎	◎	680		

LCM
LCR
LCG
LCW
LCX
STM
STG
STS/STL
STR2
UCA2
ULK*
JSK/M2
JSG
JSC3/JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3*
NHS
HRL
LN
Hand
Chuk
MechHnd/Chuk
ShkAbs
FJ
FK
SpdContr
Ending