


Y-shaped strainer

EXA
FWD
HNB/G
USB/G
FAB/G
FGB/G
FVB
FWB/G
FHB
FLB
AB
AG
AP/
AD
APK/
ADK
DryAir
EX-
XPLNprf
XPLNprf
HVB/
HVL
S ◇ B/
NAB
LAD/
NAD
Water-
Rela
NP/NAP/
NVP
SNP
CHB/G
MXB/G
Other
valves
SWD/
MWD
DustColl
CVE/
CVSE
CCH/
CPE/D
LifeSci
Gas-
Combus
Auto-
Water
Outdoor
SpecFld
Custom
Ending

Y-shaped strainer

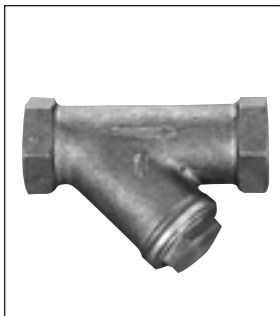


This Y-shaped strainer is used to remove foreign matter in the fluid flowing in the pipe. Maintenance of the strainer is very easy.

Specifications

Item		
Working fluid		Water
Proof pressure	MPa	2 (≈290 psi, 20 bar)
Working pressure	MPa	0 (≈0 psi, 0 bar) to 1 (≈150 psi, 10 bar)
Operating ambient temperature	°C	0 (32°F) to 60 (140°F)

Dimensions

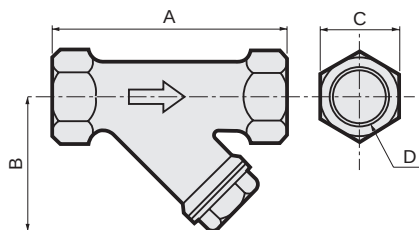

Model No.	A	B	C	D	Weight (kg)
YS-02	64	40	23	Rc1/4	0.2
YS-03	64	40	23	Rc3/8	0.2
YS-04	84	53	29	Rc1/2	0.3
YS-06	96	60	35	Rc3/4	0.4
YS-10	116	65	41	Rc1	0.7
YS-12	142	76	54	Rc1 1/4	1.3
YS-14	160	96	58	Rc1 1/2	1.8
YS-20	180	110	75	Rc2	2.8

● Main material

Body	Bronze casting
Strainer	Stainless steel

● Strainer mesh

YS-02	120 mesh
YS-03	
YS-04 to YS-20	80 mesh