



Pressure Gauge Outdoor Series

# GW49D Series

● Port size: R1/8, R1/4

JIS symbol




## Specifications

Item	GW49D	
Working fluid	Compressed air	
Fluid temperature °C	-20 to 60 (no freezing)	
Ambient temperature °C	-20 to 60	
Accuracy *1	Full scale ±3% (with 5 to 35 °C)	
Shape	D type (rear side screw, stock section hexagon)	
Display system	ø46.6	
Material	Bourdon tube	Copper alloy
	Stock	Copper alloy (nickel plating)
	Housing	Stainless steel
	Lens	Tempered glass
Pressure range MPa	0 to 1.0	
Port size R	1/8, 1/4	
Weight g	100	

\*1: The guaranteed temperature indicator accuracy is 20±15°C.

## Dimensions

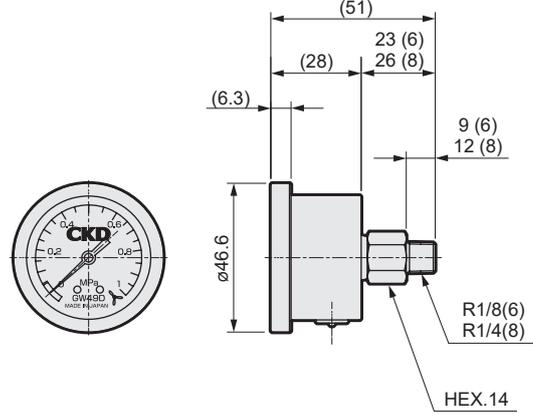

## How to order

**GW49D - 6 - P10**

**A** Model No.

**B** Port size

**C** Pressure display

Code	Description
<b>A Model No.</b>	<b>GW49D</b>
<b>B Port size</b>	<b>6 R<sup>1</sup>/<sub>8</sub></b>
	<b>8 R<sup>1</sup>/<sub>4</sub></b>
<b>C Pressure display [MPa] *1</b>	<b>P10 0 to 1.0 MPa</b>

\*1: Consult with CKD concerning psi or bar display.

Drain separator  
F.R.L. unit

Pneumatic auxiliary  
components

Pneumatic  
valves

Fluid control  
valves

Pneumatic  
cylinders

Related  
products

Safety  
precautions