



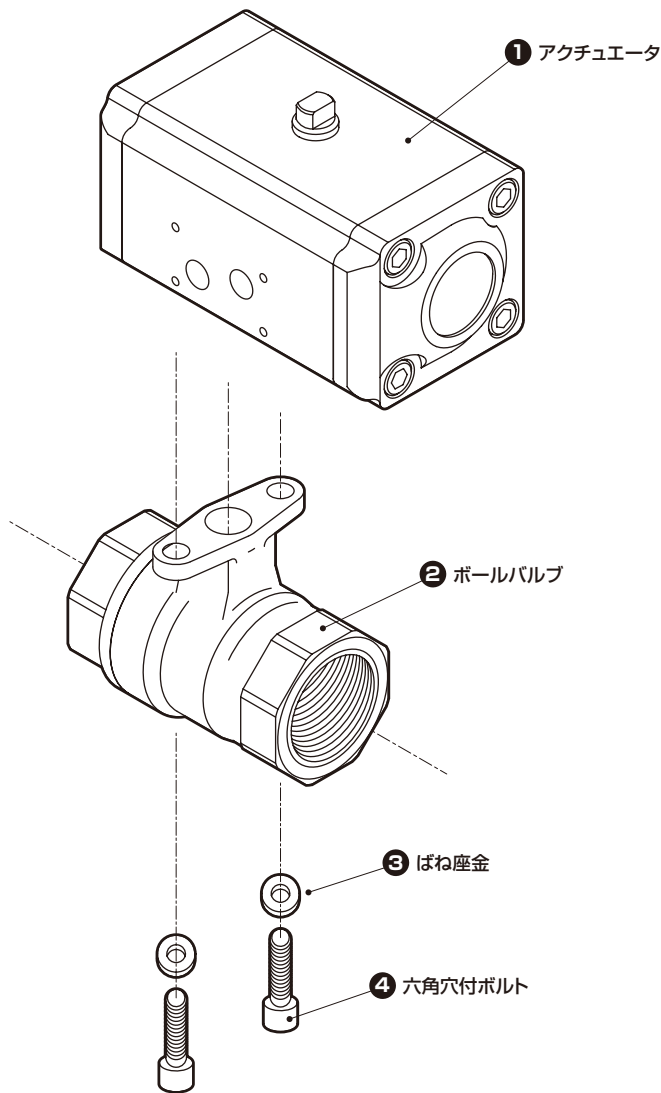
蒸気用エアオペレイト式ボールバルブ 2ポート弁  
(コンパクトロータリバルブ)

# CSB・CSB-R※ CSBF・CSBF-R※ Series

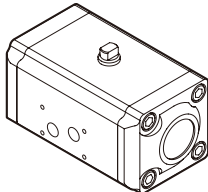
●複動作動形、単動作動形NC(ノーマルクローズ)形・NO(ノーマルオープン)形

# CSB・CSB-R※ CSBF・CSBF-R※ Series

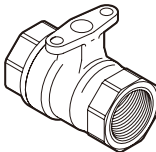
■部品展開図



●アクチュエータ組立

| 接続口径          | 部品形番       |               |               |                                                                                     | 番号          | 数量          |
|---------------|------------|---------------|---------------|-------------------------------------------------------------------------------------|-------------|-------------|
|               | 複動作動形      | R1：単動作動形 NC   | R2：単動作動形 NO   |                                                                                     |             |             |
| ■スタンダードボア CSB |            |               |               |                                                                                     |             |             |
| 10(Rc3/8)     | CSB-25-ACT | CSB-R1-20-ACT | CSB-R2-20-ACT |  | ①<br>③<br>④ | 1<br>2<br>2 |
| 15(Rc1/2)     |            |               |               |                                                                                     |             |             |
| 20(Rc3/4)     |            |               |               |                                                                                     |             |             |
| 25(Rc1)       |            |               |               |                                                                                     |             |             |
| 32(Rc1 1/4)   | CSB-50-ACT | CSB-R1-32-ACT | CSB-R2-32-ACT |                                                                                     |             |             |
| 40(Rc1 1/2)   |            | —             | —             |                                                                                     |             |             |
| 50(Rc2)       |            | —             | —             |                                                                                     |             |             |
| ■フルボア CSBF    |            |               |               |                                                                                     |             |             |
| 15(Rc1/2)     | CSB-25-ACT | CSB-R1-20-ACT | CSB-R2-20-ACT |  |             |             |
| 20(Rc3/4)     |            | CSB-R1-32-ACT | CSB-R2-32-ACT |                                                                                     |             |             |
| 25(Rc1)       | CSB-50-ACT | —             | —             |                                                                                     |             |             |
| 32(Rc1 1/4)   |            |               |               |                                                                                     |             |             |
| 40(Rc1 1/2)   |            |               |               |                                                                                     |             |             |

●ボールバルブ

| 接続口径          | 部品形番                 |                     |                                                                                       | 番号 | 数量 |
|---------------|----------------------|---------------------|---------------------------------------------------------------------------------------|----|----|
|               | ボディ・シート材質            |                     |                                                                                       |    |    |
|               | H：青銅・強化PTFE          | W：ステンレス強化PTFE       |                                                                                       |    |    |
| ■スタンダードボア CSB |                      |                     |  | ②  | 1  |
| 10(Rc3/8)     | CSB-10-H-BALL-VALVE  | CSB-10-W-BALL-VALVE |                                                                                       |    |    |
| 15(Rc1/2)     | CSB-15-H-BALL-VALVE  | CSB-15-W-BALL-VALVE |                                                                                       |    |    |
| 20(Rc3/4)     | CSB-20-H-BALL-VALVE  | CSB-20-W-BALL-VALVE |                                                                                       |    |    |
| 25(Rc1)       | CSB-25-H-BALL-VALVE  | CSB-25-W-BALL-VALVE |                                                                                       |    |    |
| 32(Rc1 1/4)   | CSB-32-H-BALL-VALVE  | CSB-32-W-BALL-VALVE |                                                                                       |    |    |
| 40(Rc1 1/2)   | CSB-40-H-BALL-VALVE  | CSB-40-W-BALL-VALVE |                                                                                       |    |    |
| 50(Rc2)       | CSB-50-H-BALL-VALVE  | CSB-50-W-BALL-VALVE |                                                                                       |    |    |
| ■フルボア CSBF    |                      |                     |                                                                                       |    |    |
| 15(Rc1/2)     | CSBF-15-H-BALL-VALVE | —                   |                                                                                       |    |    |
| 20(Rc3/4)     | CSBF-20-H-BALL-VALVE | —                   |                                                                                       |    |    |
| 25(Rc1)       | CSBF-25-H-BALL-VALVE | —                   |                                                                                       |    |    |
| 32(Rc1 1/4)   | CSBF-32-H-BALL-VALVE | —                   |                                                                                       |    |    |
| 40(Rc1 1/2)   | CSBF-40-H-BALL-VALVE | —                   |                                                                                       |    |    |