




スーパードライヤ モジュラーシリーズ

SDM4000 Series

部品展開図

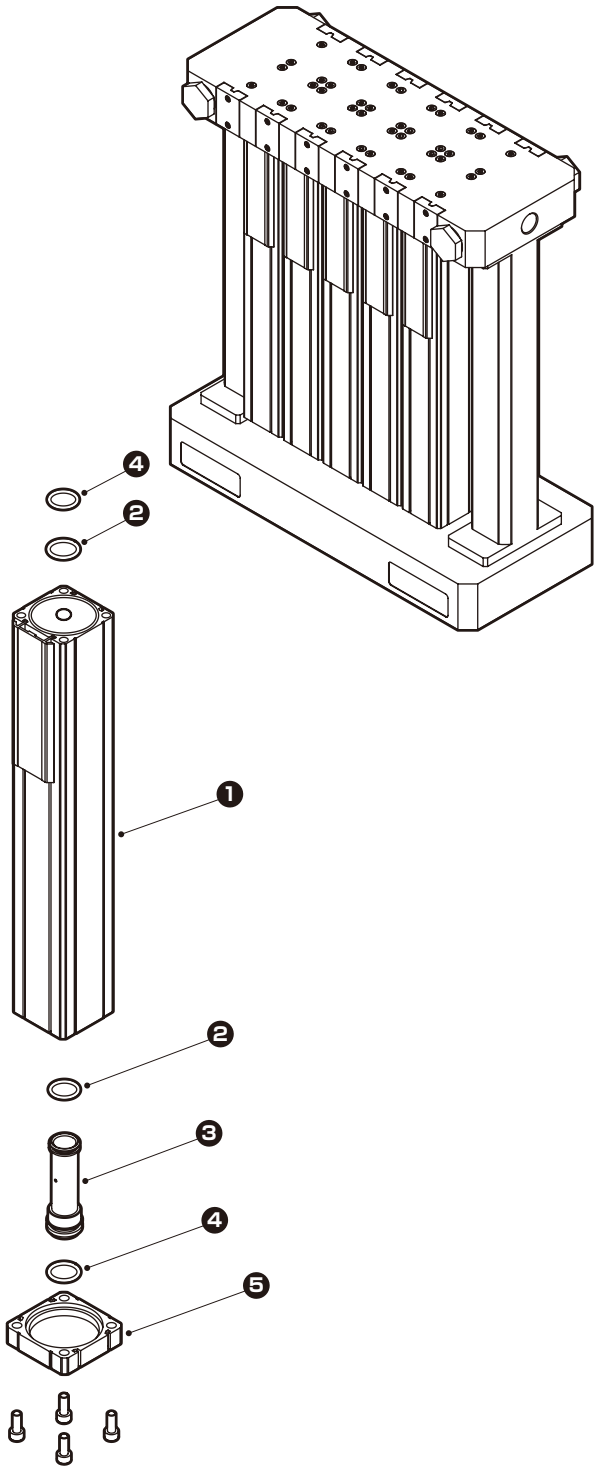

膜モジュール組立

機種形番	出口空気大気圧露点	入口空気圧力	部品形番	部品図	番号	数量
SDM4050	A (-20℃)	05 (0.5MPa)	SDM4050-A05-MEMBRANE-ASSY		① ② ③ ④ ⑤	1 2 1 2 1
		07 (0.7MPa)	SDM4050-A07-MEMBRANE-ASSY			
	B (-40℃)	05 (0.5MPa)	SDM4050-B05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4050-B07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4050-B14-MEMBRANE-ASSY			
SDM4075	A (-20℃)	05 (0.5MPa)	SDM4075-A05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4075-A07-MEMBRANE-ASSY			
	B (-40℃)	05 (0.5MPa)	SDM4075-B05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4075-B07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4075-B14-MEMBRANE-ASSY			
SDM4100	A (-20℃)	05 (0.5MPa)	SDM4100-A05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4100-A07-MEMBRANE-ASSY			
	B (-40℃)	05 (0.5MPa)	SDM4100-B05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4100-B07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4100-B14-MEMBRANE-ASSY			
	C (-60℃)	05 (0.5MPa)	SDM4050-C05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4050-C07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4050-C14-MEMBRANE-ASSY			
	A (-20℃)	05 (0.5MPa)	SDM4100-A05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4100-A07-MEMBRANE-ASSY			
	B (-40℃)	05 (0.5MPa)	SDM4100-B05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4100-B07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4100-B14-MEMBRANE-ASSY			
	C (-60℃)	05 (0.5MPa)	SDM4100-C05-MEMBRANE-ASSY			
		07 (0.7MPa)	SDM4100-C07-MEMBRANE-ASSY			
		14 (1.4MPa)	SDM4100-C14-MEMBRANE-ASSY			

●Oリングセット

部品形番	部品図	番号	数量
SD-3000/4000-ORING-SET		②	各 2
		④	