 


τ DISC 产品阵容一览

马达类型	额定 转速 (rps)	外径 (mm)	中空 直径 (mm)	规格 记载页	外形图 记载页	额定转矩 (N·m)									
						2.5	5	7.5	10	20	30	40	50	75	
ND110-65-FS (P) N(0) ND110-85-FS (P)	5	112	19	P.16	P.18	 4.2/10.5 (3.4/8.5)	 7.1/17.5 (5.9/14.7)								
ND140-65-FS (P) N(0)	5	145	19	P.16	P.19	() 内为AC100V规格	() 内为AC100V规格	 9.6/22							
ND140-70-LS (P) N(0) ND140-95-LS (P) N(0)	5	145	19	P.16	P.19 P.20			 9.6/22	 15/37						
ND180-55-FS (P)	5	180	30	P.16	P.20				 17/40						
ND180-70-LS (P) ND180-95-LS (P) N(0)	5	180	35	P.17	P.21				 17/40	 30/75					
ND250-55-FS (P)	3	254	65	P.17	P.22					 42/100					
ND250-70-LS (P) ND250-95-LS (P) N(0)	3	260	65	P.17	P.22 P.23					 42/100	 80/190				
ND400-65-FS (P)	2	408	65	P.17	P.23										
ND400-70-LS (P) ND400-95-LS (P) ND400-160-LS (P)	2	408	65	P.17	P.24 P.25										
ND110-85-FS (P) -HS	15	112	19	P.26	P.27			 8/19.2							
ND140-70-LS (P) -HS ND140-95-LS (P) -HS	11	145	19	P.26	P.27 P.28			 9.6/22	 15/37						
ND180-95-LS (P) -HS	11	180	35	P.26	P.28				 24/65						
DD160-96-LS (P5/P3) DD160-105-FS (P5/P3) DD160-146-LS (P5/P3)	4	160	25 60 25	P.30	P.32 P.33			 10/23	 10/23	 27/62.5					
DD250-90-LS (P5/P3) DD250-138-LS (P5/P3) DD250-163-LS (P5/P3)	2	265	65	P.30	P.33 P.34					 42/100	 80/190				
DD400-150-LS (P5/P3) DD400-200-LS (P5/P3) DD400-250-LS (P5/P3)	2 2 1/1.5/2	420	65	P.31	P.35 P.36 P.37										
DD630-175-LS (P10/P5) DD630-225-LS (P10/P5)	1	663	150	P.31	P.37 P.38										
HD140-160-LS (P) N(0)	6	140	30	P.39	P.40					 27/67.5					
HD140-185-LS (P) N(0)	5.5	140	30	P.39	P.41					 36/100					
HD180-200-LS (P)	6	180	35	P.39	P.41						 68/145				



形状：无法兰类型
额定转矩/最大转矩 (N·m)




形状：带法兰类型
额定转矩/最大转矩 (N·m)

100 125 150 200 250 300 500 1000 1500 3000


τ DISC[®] Servo Motor **ND-s**
series

标准类型

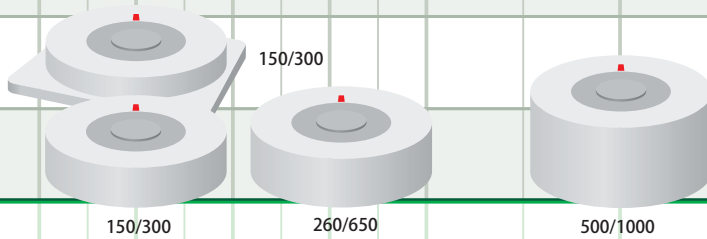

τ DISC[®] Servo Motor **ND-s HS**
series

高速旋转类型

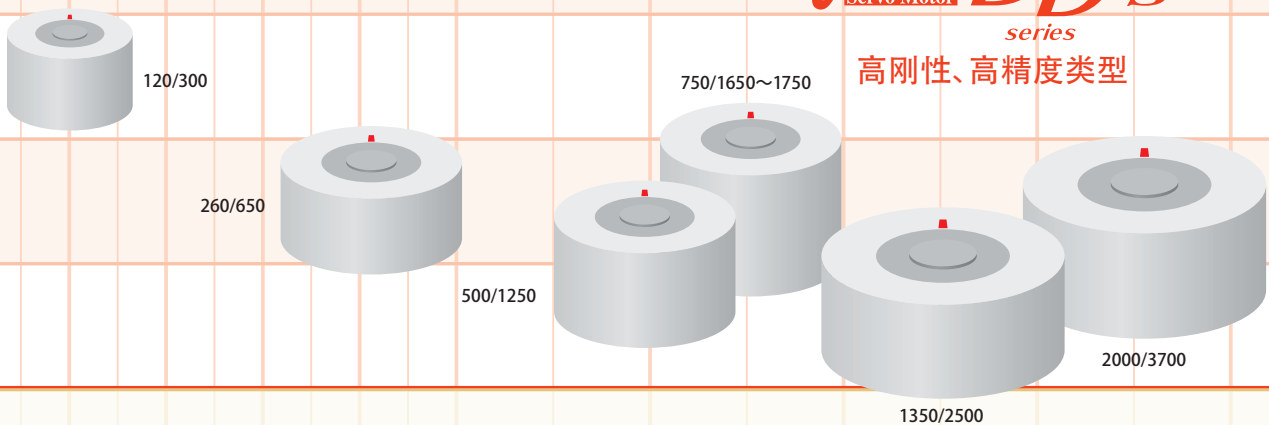

τ DISC[®] Servo Motor **DD-s**
series

高刚性、高精度类型

τ DISC[®] Servo Motor **HD-s**
series

高响应类型