


安装螺栓型号表示方法

SSD - BOLT - d×L

安装螺栓(螺栓4个1套。)

一览表的查看方法

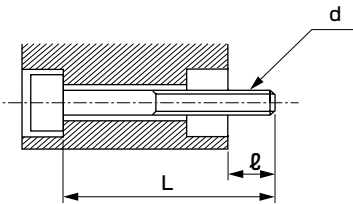

材质：钢
处理：发黑处理

d：安装螺栓螺纹直径
L：安装螺栓长度
φ：配套侧可拧入长度
(注)安装螺栓用d×L表示。

SSD-□用

型 号	φ	d×L
SSD-12- 5	6.5	M3×25
10		×30
15		×35
20		×40
25		×45
30		×50
SSD-16- 5	6.5	M3×25
10		×30
15		×35
20		×40
25		×45
30		×50
SSD-20- 5	6	M5×25
10		×30
15		×35
20		×40
25		×45
30		×50
SSD-25- 5	8	M5×30
10		×35
15		×40
20		×45
25		×50
30		×55
40		×65
50		×75
SSD-32- 5	7.5	M5×30
10		×35
15		×40
20		×45
25		×50
30		×55
40		×65
50		×75

型 号	φ	d×L
SSD-40- 5	6	M5× 35
10		× 40
15		× 45
20		× 50
25		× 55
30		× 60
40		× 70
50		× 80
SSD-50- 5	11	M6× 40
10		× 45
15		× 50
20		× 55
25		× 60
30		× 65
40		× 75
50		× 85
SSD-63- 5	13	M8× 45
10		× 50
20		× 60
30		× 70
40		× 80
50		× 90
SSD-80- 5	17.5	M10× 55
10		× 60
20		× 70
30		× 80
40		× 90
50		×100

型 号	φ	d×L
SSD-100- 5	18	M10× 65
10		× 70
20		× 80
30		× 90
40		×100
50		×110
SSD-125- 10	21	M12× 90
20		×100
30		×110
40		×120
50		×130
60		×140
70		×150
80		×160
90		×170
100		×180
SSD-140- 10	21	M12×100
20		×110
30		×120
40		×130
50		×140
60		×150
70		×160
80		×170
90		×180
100		×190
SSD-160- 10	24.2	M14×100
20		×110
30		×120
40		×130
50		×140
60		×150
70		×160
80		×170
90		×180
100		×190

SSD-L-□用

型 号	ℓ	d×L
SSD-L-12- 5	6.5	M3×35
10		×35
15		×40
20		×45
25		×50
30		×55
SSD-L-16- 5	6.5	M3×35
10		×35
15		×40
20		×45
25		×50
30		×55
SSD-L-20- 5	6	M5×35
10		×40
15		×45
20		×50
25		×55
30		×60
SSD-L-25- 5	8	M5×40
10		×45
15		×50
20		×55
25		×60
30		×65
40		×75
50		×85
SSD-L-32- 5	7.5	M5×40
10		×45
15		×50
20		×55
25		×60
30		×65
40		×75
50		×85

型 号	ℓ	d×L
SSD-L-40- 5	6	M5× 45
10		× 50
15		× 55
20		× 60
25		× 65
30		× 70
40		× 80
50		× 90
SSD-L-50- 5	11	M6× 50
10		× 55
15		× 60
20		× 65
25		× 70
30		× 75
40		× 85
50		× 95
SSD-L-63- 5	13	M8× 55
10		× 60
20		× 70
30		× 80
40		× 90
50		×100
SSD-L-80- 5	17.5	M10× 65
10		× 70
20		× 80
30		× 90
40		×100
50		×110

型 号	ℓ	d×L
SSD-L-100- 5	18	M10× 75
10		× 80
20		× 90
30		×100
40		×110
50		×120
SSD-L-125- 10	21	M12× 90
20		×100
30		×110
40		×120
50		×130
60		×140
70		×150
80		×160
90		×170
100		×180
SSD-L-140- 10	21	M12×100
20		×110
30		×120
40		×130
50		×140
60		×150
70		×160
80		×170
90		×180
100		×190
SSD-L-160- 10	24.2	M14×100
20		×110
30		×120
40		×130
50		×140
60		×150
70		×160
80		×170
90		×180
100		×190

SSD- $\frac{X}{Y}$ -□用

型 号	ℓ	d×L
SSD- $\frac{X}{Y}$ -12- 5	6.5	M3×25
10		×30
-16- 5		M3×25
10	6	×30
-20- 5		M5×25
10		×30

型 号	ℓ	d×L
SSD- $\frac{X}{Y}$ -25- 5	8	M5×30
10		×35
-32- 5	7.5	M5×30
10		×35
-40-10	6	M5×40
20		×50

型 号	ℓ	d×L
SSD- $\frac{X}{Y}$ -50-10	11	M6×45
20		×55

SSD- $\frac{XL}{YL}$ -□用

型 号	ℓ	d×L
SSD- $\frac{XL}{YL}$ -12- 5	6.5	M3×35
10		×35
-16- 5		M3×35
10	6	×35
-20- 5		M5×35
10		×40

型 号	ℓ	d×L
SSD- $\frac{XL}{YL}$ -25- 5	8	M5×40
10		×45
-32- 5	7.5	M5×40
10		×45
-40-10	6	M5×50
20		×60

型 号	ℓ	d×L
SSD- $\frac{XL}{YL}$ -50-10	11	M6×55
20		×65

SCP#3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

SCP#3	SSD-D-□用			型 号	ℓ	d×L	型 号	ℓ	d×L	型 号	ℓ	d×L			
CMK2	SSD-D-12- 5	6.5	M3×30	10		×35	SSD-D-40- 5	6.5	M5× 45	SSD-D-125- 10	21	M12× 90			
				15		×40			× 50			×100			
				20		×45			× 55			×110			
CMA2	25		×50		× 60	20		× 65	40		×120				
					25			× 70			50	×130			
SCM	30		×55		× 80	30		× 90	60		×140				
					40			× 90			70	×150			
SCG	SSD-D-16- 5	6.5	M3×30	10		×35	SSD-D-50- 5	7.5	M6× 45	80		×160			
				15		×40			× 50			90	×170		
				20		×45			× 55			100	×180		
SCA2	25		×50		× 60	30		× 65	SSD-D-140- 10	21	M12 ×100				
					40			× 70			× 65	20	×110		
					50			× 80			× 65	30	×120		
SCS2	SSD-D-20- 5	9.5	M5×35	10		×40	25		× 70	40		×130			
				15		×45			× 80			50	×140		
				20		×50			× 90			60	×150		
CKV2	25		×55		× 60	SSD-D-63- 5	13	M8× 50	70		×160				
					30			× 55			80	×170			
					40			× 65			90	×180			
CAV2・COVP/N2	SSD-D-25- 5	9.5	M5×40	10		×45	20		× 75	100		×190			
				15		×50			× 85			SSD-D-160- 10	24.2	M14 ×100	
				20		×55			× 95			20		×110	
SSD2	25		×60		× 65	SSD-D-80- 5	12.5	M10× 55	30		×120				
					30			× 75			× 60	40	×130		
					40			× 85			× 70	50	×140		
SSD	50		×85		×100	20		× 80	60		×150				
					30			× 90			70	×160			
					40			×100			80	×170			
CAT	SSD-D-32- 5	10	M5×40	10		×45	SSD-D-100- 5	13	M10× 65	90		×180			
				15		×50			× 70			100	×190		
				20		×55			× 80						
MDC2	25		×60		× 65	10		× 70	SSD-DL-125- 10	21					
					30			× 75					× 65	20	×100
					40			× 85					× 65	30	×110
MVC	50		×85		×100	20		× 80	40		×120				
					30			× 90			50	×130			
					40			×100			60	×140			
SMG	SSD-D-40- 5	6.5	M5× 45	10		× 50	SSD-DL-50- 5	7.5	M6× 55	70		×150			
				15		× 55			× 60			80	×160		
				20		× 60			× 65			90	×170		
MSD・MSDG	10		×65		× 70	25		× 75	100		×180				
					15			× 80			× 70	SSD-DL-140- 10	21	M12 ×100	
					20			× 90			× 75	20		×110	
FC※	SSD-DL-12- 5	6.5	M3× 35	10		× 40	SSD-DL-80- 5	12.5	M10× 65	30		×120			
				15		× 45			× 70			40	×130		
				20		× 50			× 80			50	×140		
STK	25		× 55		× 60	30		× 90	60		×150				
					30			×100			70	×160			
					40			×110			80	×170			
SRL3	SSD-DL-16- 5	9.5	M3× 35	10		× 40	SSD-DL-100- 5	13	M10× 75	90		×180			
				15		× 45			× 85			100	×190		
				20		× 50			× 95			SSD-DL-160- 10	24.2	M14 ×100	
SRG3	25		× 55		× 60	10		× 65	20		×110				
					30			× 70			× 65	30		×120	
					40			× 80			× 70	40	×130		
SRM3	SSD-DL-20- 5	14.5	M5× 45	10		× 50	SSD-DL-125- 10	6.5	× 65	50		×140			
				15		× 55			× 70			60	×150		
				20		× 60			× 75			70	×160		
MRL2	25		× 65		× 70	30		× 80	80		×170				
					40			× 90			× 75	90	×180		
					50			×100			× 80	100	×190		
MRG2	SSD-DL-25- 5	9.5	M5× 50	10		× 55	SSD-DL-140- 10	7.5	M6× 55	20		×100			
				15		× 60			× 60			30	×110		
				20		× 65			× 65			40	×120		
SM-25	25		× 70		× 75	50		× 80	SSD-DL-160- 10	24.2		×130			
					30			× 85				× 80	20	×140	
					40			× 95				× 85	30	×150	
缓冲器	SSD-DL-32- 5	10	M5× 50	10		× 55	SSD-DL-100- 5	13	M10× 75	40		×160			
				15		× 60			× 80			50	×170		
				20		× 65			× 85			60	×180		
FJ	10		× 75		× 90	20		× 90	80		×190				
					30			×100			× 90	90	×180		
					40			×110			× 95	100	×190		
FK	50		×85		×120	30		×100	SSD-DL-125- 10	6.5					
					40			×110					× 65	20	×100
					50			×120					× 70	30	×110
调速阀	SSD-DL-40- 5	6.5	M5× 45	10		× 50	SSD-DL-80- 5	12.5	M10× 65	40		×120			
				15		× 55			× 70			50	×130		
				20		× 60			× 80			60	×140		
卷末	25		× 65		× 70	30		× 80	SSD-DL-140- 10	21		×150			
					40			× 90				× 75	50	×160	
					50			×100				× 85	60	×170	

SSD-K-□用

型 号	ℓ	d×L
SSD-K-12- 5	6.5	M3× 30
10		× 35
15		× 40
20		× 45
25		× 50
30		× 55
40		× 65
50		× 75
SSD-K-16- 5	6.5	M3× 30
10		× 35
15		× 40
20		× 45
25		× 50
30		× 55
40		× 65
50		× 75
SSD-K-20- 5	6	M5× 30
10		× 35
15		× 40
20		× 45
25		× 50
30		× 55
40		× 65
50		× 75
SSD-K-25- 10	8	M5× 40
15		× 45
20		× 50
25		× 55
30		× 60
40		× 70
50		× 80
60		× 90
70		×100
80		×110
90		×120
100		×130

型 号	ℓ	d×L
SSD-K-32- 10	12.5	M5× 50
15		× 55
20		× 60
25		× 65
30		× 70
40		× 80
50		× 90
60		×100
70		×110
80		×120
90		×130
100		×140
SSD-K-40- 10	6	M5× 50
15		× 55
20		× 60
25		× 65
30		× 70
40		× 80
50		× 90
60		×100
70		×110
80		×120
90		×130
100		×140
SSD-K-50- 10	11	M6× 55
15		× 60
20		× 65
25		× 70
30		× 75
40		× 85
50		× 95
60		×110
70		×120
80		×130
90		×140
100		×150

型 号	ℓ	d×L
SSD-K-63- 10	13	M8× 60
20		× 70
30		× 80
40		× 90
50		×100
60		×110
70		×120
80		×130
90		×140
100		×150
SSD-K-80- 10	17.5	M10× 70
20		× 80
30		× 90
40		×100
50		×110
60		×120
70		×130
80		×140
90		×150
100		×160
SSD-K-100- 10	18	M10× 80
20		× 90
30		×100
40		×110
50		×120
60		×130
70		×140
80		×150
90		×160
100		×170

SCP※3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

SCP#3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・ COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・ MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

SSD-KL-□□用

型 号	ℓ	d×L
SSD-KL-12- 5	6.5	M3× 35
10		× 40
15		× 45
20		× 50
25		× 55
30		× 60
40		× 70
50		× 80
SSD-KL-16- 5	6.5	M3× 35
10		× 40
15		× 45
20		× 50
25		× 55
30		× 60
40		× 70
50		× 80
SSD-KL-20- 5	6	M5× 40
10		× 45
15		× 50
20		× 55
25		× 60
30		× 65
40		× 75
50		× 85
SSD-KL-25- 10	8	M5× 50
15		× 55
20		× 60
25		× 65
30		× 70
40		× 80
50		× 90
60		×100
70		×110
80		×120
90		×130
100		×140

型 号	ℓ	d×L
SSD-KL-32- 10	12.5	M5× 60
15		× 65
20		× 70
25		× 75
30		× 80
40		× 90
50		×100
60		×110
70		×120
80		×130
90		×140
100		×150
SSD-KL-40- 10	6	M5× 60
15		× 65
20		× 70
25		× 75
30		× 80
40		× 90
50		×100
60		×110
70		×120
80		×130
90		×140
100		×150
SSD-KL-50- 10	11	M6× 65
15		× 70
20		× 75
25		× 80
30		× 85
40		× 95
50		×110
60		×120
70		×130
80		×140
90		×150
100		×160

型 号	ℓ	d×L
SSD-KL-63- 10	13	M8× 70
20		× 80
30		× 90
40		×100
50		×110
60		×120
70		×130
80		×140
90		×150
100		×160
SSD-KL-80- 10	17.5	M10× 80
20		× 90
30		×100
40		×110
50		×120
60		×130
70		×140
80		×150
90		×160
100		×170
SSD-KL-100- 10	18	M10× 90
20		×100
30		×110
40		×120
50		×130
60		×140
70		×150
80		×160
90		×170
100		×180

SSD-M-□用

型 号	ℓ	d×L
SSD-M-12- 5	6.5	M3×30
10		×35
15		×40
20		×45
25		×50
30		×55
SSD-M-16- 5	6.5	M3×30
10		×35
15		×40
20		×45
25		×50
30		×55
SSD-M-20- 5	6	M5×30
10		×35
15		×40
20		×45
25		×50
30		×55
SSD-M-25- 5	8	M5×35
10		×40
15		×45
20		×50
25		×55
30		×60
40		×70
50		×80

型 号	ℓ	d×L
SSD-M-32- 5	7.5	M5×40
10		×45
15		×50
20		×55
25		×60
30		×65
40		×75
50		×85
SSD-M-40- 5	6	M5×40
10		×45
15		×50
20		×55
25		×60
30		×65
40		×75
50		×85
SSD-M-50- 5	11	M6×45
10		×50
15		×55
20		×60
25		×65
30		×70
40		×80
50		×90

型 号	ℓ	d×L
SSD-M-63- 5	13	M8×50
10		×55
20		×65
30		×75
40		×85
50		×95

SSD-ML-□用

型 号	ℓ	d×L
SSD-ML-12- 5	6.5	M3×40
10		×40
15		×45
20		×50
25		×55
30		×60
SSD-ML-16- 5	6.5	M3×40
10		×40
15		×45
20		×50
25		×55
30		×60
SSD-ML-20- 5	6	M5×40
10		×45
15		×50
20		×55
25		×60
30		×65
SSD-ML-25- 5	8	M5×45
10		×50
15		×55
20		×60
25		×65
30		×70
40		×80
50		×90

型 号	ℓ	d×L
SSD-ML-32- 5	7.5	M5× 50
10		× 55
15		× 60
20		× 65
25		× 70
30		× 75
40		× 85
50		×100
SSD-ML-40- 5	6	M5× 50
10		× 55
15		× 60
20		× 65
25		× 70
30		× 75
40		× 85
50		×100
SSD-ML-50- 5	11	M6× 55
10		× 60
15		× 65
20		× 70
25		× 75
30		× 80
40		× 90
50		×100

型 号	ℓ	d×L
SSD-ML-63- 5	13	M8× 60
10		× 65
20		× 75
30		× 85
40		× 95
50		×110

SCP※3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

SSD-Q H/R用

型号	ℓ	$d \times L$
SSD-Q-16- 5	5.5	M3× 60
10		× 65
15		× 70
20		× 75
25		× 80
30		× 90
40	10.5	× 100
50	关于无法获得的螺母, 请采取缸体螺纹式安装。	
SSD-Q-20- 5	12.5	M5× 65
10		× 70
15		× 75
20		× 80
25		× 85
30		× 90
40		× 100
50		× 110

型号	ℓ	$d \times L$
SSD-Q-25- 10	9.5	M5× 70
15		× 75
20		× 80
25		× 85
30		× 90
40		×100
50		×110
60		×120
70		×130
80		×140
90		×150
100	×160	
SSD-Q-32- 10	13.5	M5× 80
15		× 85
20		× 90
25		× 95
30		×100
40		×110
50		×120
60		×130
70		×140
80		×150
90		×160
100	×170	

型号	ℓ	$d \times L$
SSD-Q-40- 10	10	M5× 90
15		× 95
20		×100
25		×105
30		×110
40		×120
50		×130
60		×140
70		×150
80		×160
90		×170
100		×180
SSD-Q-50- 10	12	M6×110
15		×115
20		×120
25		×125
30		×130
40		×140
50		×150
60		×160
70		×170
80		×180
90		×190
100		×200

型号	ℓ	$d \times L$
SSD-Q-63-	10	M8×120
	20	×130
	30	×140
	40	×150
	50	×160
	60	×170
	70	×180
	80	×190
	90	×200
	100	×210
SSD-Q-80-	10	M10×140
	20	×150
	30	×160
	40	×170
	50	×180
	60	×190
	70	×200
	80	×210
	90	×220
	100	×230
SSD-Q-100-	10	M10×140
	20	×150
	30	×160
	40	×170
	50	×180
	60	×190
	70	×200
	80	×210
	90	×220
	100	×230

SSD-QL H/R用

型号	ℓ	$d \times L$
SSD-QL-16- 5	5.5	M3× 65
10		× 70
15		× 75
20		× 80
25		× 90
30		× 90
40	5.5	× 100
50	因没有配套螺母, 请采取缸体螺纹式安装。	
SSD-QL-20- 5	12.5	M5× 75
10		× 80
15		× 85
20		× 90
25		× 95
30		× 100
40		× 110
50		× 120

型号	ℓ	$d \times L$
SSD-QL-25- 10	9.5	M5× 80
15		× 85
20		× 90
25		× 95
30		×100
40		×110
50		×120
60		×130
70		×140
80		×150
90		×160
100	×170	
SSD-QL-32- 10	13.5	M5× 90
15		× 95
20		×100
25		×105
30		×110
40		×120
50		×130
60		×140
70		×150
80		×160
90		×170
100	×180	

型号	ℓ	$d \times L$
SSD-QL-40- 10	10	M5×100
15		×105
20		×110
25		×115
30		×120
40		×130
50		×140
60		×150
70		×160
80		×170
90		×180
100		×190
SSD-QL-50- 10	12	M6×120
15		×125
20		×130
25		×135
30		×140
40		×150
50		×160
60		×170
70		×180
80		×190
90		×200
100		×210

型号	ℓ	d × L
SSD-QL-63- 10	19	M8×130
20		×140
30		×150
40		×160
50		×170
60		×180
70		×190
80		×200
90		×210
100		×220
SSD-QL-80- 10	12	M10×150
20		×160
30		×170
40		×180
50		×190
60		×200
70		×210
80		×220
90		×230
100		×240
SSD-QL-100- 10	12	M10×150
20		×160
30		×170
40		×180
50		×190
60		×200
70		×210
80		×220
90		×230
100		×240