


SCP※3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

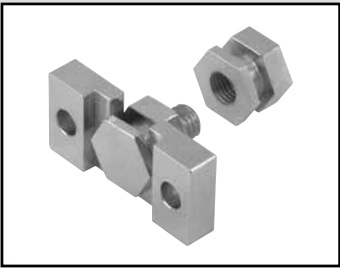

简易万向节

FK Series

● 适用缸径：φ6～φ100



规格

型号		允许负荷 注1 (N)	允许偏心量 (mm)	推力方向的 间隙量(mm)
外螺纹	内螺纹			
FK-M3-N	FK-M3	63	±0.3	0.1~0.3
FK-M4-N	FK-M4	110		
FK-M5-N	FK-M5	179		
FK-M6-N	FK-M6	253		
FK-M8-N	FK-M8×1.0	462		
——	FK-M8×1.25	462		
FK-M10-N	FK-M10	734		
——	FK-M12	1069	±0.7	
——	FK-M14	1466		
FK-M16-N	FK-M16	2003		
——	FK-M18	2448		
FK-M20-N	——	3130		
——	FK-M22	3896		
——	FK-M26	6219		

注1：允许负荷表示静态负荷。

型号表示方法

● 简易万向节

FK - M3-N

机种型号

Ⓐ 螺纹尺寸

符号	内容	
A 螺纹尺寸		
M3-N	M3×0.5	外 螺 纹 型
M4-N	M4×0.7	
M5-N	M5×0.8	
M6-N	M6×1.0	
M8-N	M8×1.25	
M10-N	M10×1.5	
M16-N	M16×2.0	
M20-N	M20×2.5	
M3	M3×0.5	内 螺 纹 型
M4	M4×0.7	
M5	M5×0.8	
M6	M6×1.0	
M8×1.0	M8×1.0	
M8×1.25	M8×1.25	
M10	M10×1.25	
M12	M12×1.5	
M14	M14×1.5	
M16	M16×1.5	
M18	M18×1.5	
M22	M22×1.5	
M26	M26×1.5	

二次电池对应规格 (样本编号：CC-1226C)

FK - (螺纹尺寸) - P40 ● 二次电池生产工艺中可使用的结构。


※详情请垂询本公司。

外形尺寸图




● 部件(1)

材 质：钢
表面处理：镀镍

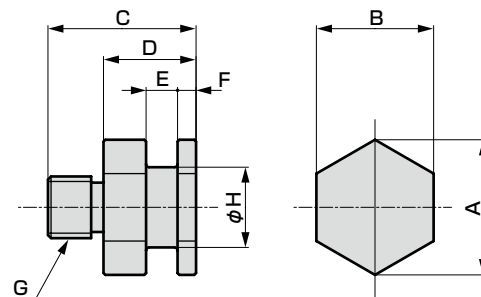

● 部件(2)

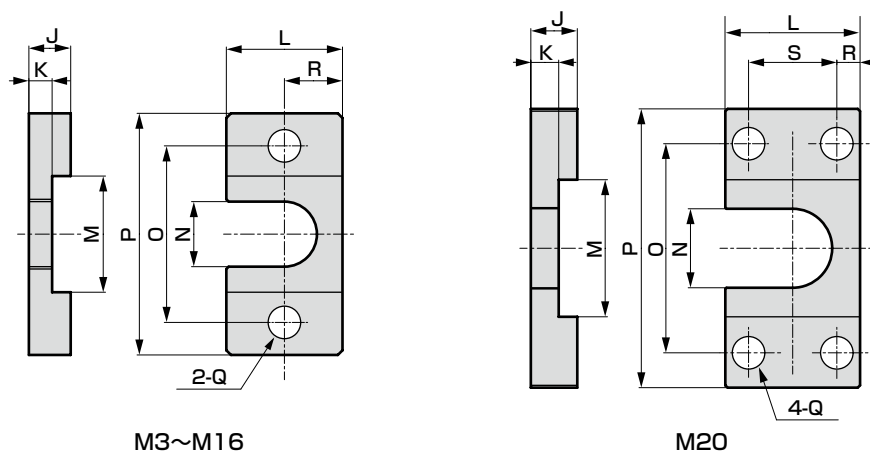

部件(1)

型号	适用气缸	A	B	C	D	E	F	G	H	重量 g
FK-M3-N	SSD・SSD2-12	11.6	10	15	10	3.1 ^{+0.1} ₀	2	M3×0.5	6	5.3
FK-M4-N	SSD・SSD2-16	11.6	10	15.5	10	3.1 ^{+0.1} ₀	2	M4×0.7	6	5.5
FK-M5-N	SSD・SSD2-20,FCD-25	13.9	12	16.5	10	3.1 ^{+0.1} ₀	2	M5×0.8	8	8.3
FK-M6-N	SSD・SSD2-25,FCD-32	13.9	12	19	10	3.1 ^{+0.1} ₀	2	M6×1.0	8	8.9
FK-M8-N	SSD・SSD2-32,40,FCD-40,50	21.9	19	23	15	5.1 ^{+0.1} ₀	3	M8×1.25	13	30.8
FK-M10-N	SSD・SSD2-50,63,FCD-63	21.9	19	24	15	5.1 ^{+0.1} ₀	3	M10×1.5	13	32.7
FK-M16-N	SSD・SSD2-80	37	32	31	20	7.1 ^{+0.1} ₀	4	M16×2.0	23	122.5
FK-M20-N	SSD・SSD2-100	53.1	46	43	28	12.1 ^{+0.1} ₀	7	M20×2.5	32	333

部件(2)

型号	适用气缸	J	K	L	M	N	O	P	Q	R	S	重量 g
FK-M3-N	SSD・SSD2-12	6	3 ⁰ _{0.1}	16	14	7	24	34	4.5	8	—	16
FK-M4-N	SSD・SSD2-16	6	3 ⁰ _{0.1}	16	14	7	24	34	4.5	8	—	16
FK-M5-N	SSD・SSD2-20,FCD-25	6	3 ⁰ _{0.1}	19	16	9	26	36	4.5	9.5	—	19.6
FK-M6-N	SSD・SSD2-25,FCD-32	6	3 ⁰ _{0.1}	19	16	9	26	36	4.5	9.5	—	19.6
FK-M8-N	SSD・SSD2-32,40,FCD-40,50	9	5 ⁰ _{0.1}	25	25	14	38	52	7	12.5	—	54.5
FK-M10-N	SSD・SSD2-50,63,FCD-63	9	5 ⁰ _{0.1}	25	25	14	38	52	7	12.5	—	54.5
FK-M16-N	SSD・SSD2-80	12	7 ⁰ _{0.1}	44	42	25	62	85	11	22	—	216
FK-M20-N	SSD・SSD2-100	22	12 ⁰ _{0.1}	65	59	34	90	120	14	13.5	38	788


SCP*3
CMK2
CMA2
SCM
SCG
SCA2
SCS2
CKV2
CAV2・COVP/N2
SSD2
SSG
SSD
CAT
MDC2
MVC
SMG
MSD・MSDG
FC※
STK
SRL3
SRG3
SRM3
SRT3
MRL2
MRG2
SM-25
缓冲器
FJ
FK
调速阀
卷末

外形尺寸图





材 质：钢
表面处理：镀镍

● 部件(1)

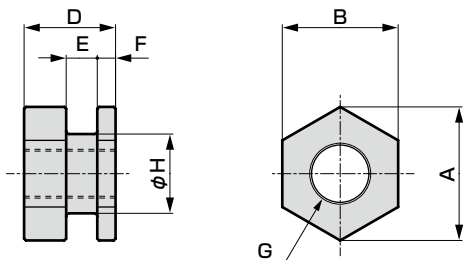

● 部件(2)

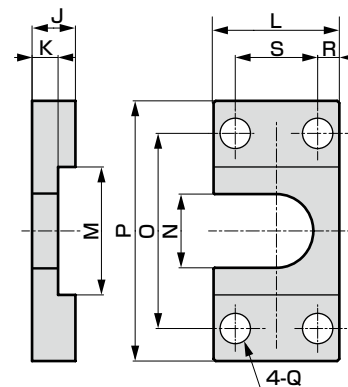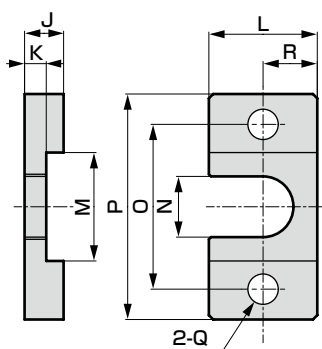

M3~M18

M22~M26

部件(1)

型号	适用气缸	A	B	D	E	F	G	H	重量 g
FK-M3	SCPD3-6,CAT-6,SMG-6	11.6	10	10	$3.1^{+0.1}_0$	2	M3×0.5	6	4.6
FK-M4	SCPD3-10,CAT-10,SMG-10	11.6	10	10	$3.1^{+0.1}_0$	2	M4×0.7	6	4.1
FK-M5	SCPD3-16,CAT-15,SMG-16 SSD-12-N	13.9	12	10	$3.1^{+0.1}_0$	2	M5×0.8	8	6.2
FK-M6	SMG-20,SSD・SSD2-16-N	13.9	12	10	$3.1^{+0.1}_0$	2	M6×1.0	8	5.7
FK-M8×1.0	CMK2-20,CMA2-20,JSK2-20,JSM2-20	21.9	19	15	$5.1^{+0.1}_0$	3	M8×1.0	13	23
FK-M8×1.25	SMG-25,SSD・SSD2-20-N,SCM-20	21.9	19	15	$5.1^{+0.1}_0$	3	M8×1.25	13	23.4
FK-M10	CMK2-25・32,CMA2-30,SMG-32,SSD・SSD2-25-N, SCG-32,SCM-25・32,FCD-25-N,JSK2-25・32,JSM2-30	21.9	19	15	$5.1^{+0.1}_0$	3	M10×1.25	13	20.2
FK-M12	CMK2-40,CMA2-40,JSK2-40,JSM2-40	27.7	24	15	$5.1^{+0.1}_0$	3	M12×1.5	18	35.7
FK-M14	SCA2-40,SSD・SSD2-32・40-N・SCG-40, SCM-40,FCD-32・40-N,JSC3-40	27.7	24	15	$5.1^{+0.1}_0$	3	M14×1.5	18	31.2
FK-M16	CAV2-50	37	32	20	$7.1^{+0.1}_0$	4	M16×1.5	23	81.3
FK-M18	SCA2-50・63,SSD・SSD2-50・63-N,SCM-50・63, SCG-50・63,FCD-50・63-N,JSC3-50・63	37	32	20	$7.1^{+0.1}_0$	4	M18×1.5	23	73.1
FK-M22	SCA2-80,SSD・SSD2-80-N,JSC3-80, SCG-80,SCM-80,CAV2-75・100	53.1	46	28	$12.1^{+0.1}_0$	7	M22×1.5	32	226
FK-M26	SCA2-100,SSD・SSD2-100-N,SCM-100,JSC3-100,SCG-100	53.1	46	28	$12.1^{+0.1}_0$	7	M26×1.5	32	193

部件(2)

型号	适用气缸	J	K	L	M	N	O	P	Q	R	S	重量 g
FK-M3	SCPD3-6,CAT-6,SMG-6	6	3^{+0}_0	16	14	7	24	34	4.5	8	—	16
FK-M4	SCPD3-10,CAT-10,SMG-10	6	3^{+0}_0	16	14	7	24	34	4.5	8	—	16
FK-M5	SCPD3-16,CAT-15,SMG-16 SSD・SSD2-12-N	6	3^{+0}_0	19	16	9	26	36	4.5	9.5	—	19.6
FK-M6	SMG-20,SSD・SSD2-16-N	6	3^{+0}_0	19	16	9	26	36	4.5	9.5	—	19.6
FK-M8×1.0	CMK2-20,CMA2-20,JSK2-20,JSM2-20	9	5^{+0}_0	25	25	14	38	52	7	12.5	—	54.5
FK-M8×1.25	SMG-25,SSD・SSD2-20-N,SCM-20	9	5^{+0}_0	25	25	14	38	52	7	12.5	—	54.5
FK-M10	CMK2-25・32,CMA2-30,SMG-32,SSD・SSD2-25-N, SCG-32,SCM-25・32,FCD-25-N,JSK2-25・32,JSM2-30	9	5^{+0}_0	25	25	14	38	52	7	12.5	—	54.5
FK-M12	CMK2-40,CMA2-40	9	5^{+0}_0	32	32	19	50	70	9	16	—	94.5
FK-M14	SCA2-40,SSD・SSD2-32・40-N・SCG-40, SCM-40,FCD-32・40-N,JSC3-40	9	5^{+0}_0	32	32	19	50	70	9	16	—	94.5
FK-M16	CAV2-50	12	7^{+0}_0	44	42	25	62	85	11	22	—	216
FK-M18	SCA2-50・63,SSD・SSD2-50・63-N,SCM-50・63, SCG-50・63,FCD-50・63-N,JSC3-50・63	12	7^{+0}_0	44	42	25	62	85	11	22	—	216
FK-M22	SCA2-80,SSD・SSD2-80-N,JSC3-80, SCG-80,SCM-80,CAV2-75・100	22	12^{+0}_0	65	59	34	90	120	14	13.5	38	788
FK-M26	SCA2-100,SSD・SSD2-100-N,SCM-100,JSC3-100,SCG-100	22	12^{+0}_0	65	59	34	90	120	14	13.5	38	788