

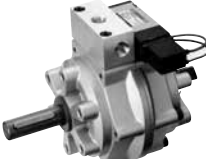
● 小型(RV3※1~RV3※30)

●：标准、○：准标准、■：不可制作

种类	型号		叶片型	有效扭矩 (0.5MPa时) (N·m)	摆动角度					带开关 “气口位置轴向 带开关时不适用”	带法兰部件	带脚座部件	带缓冲器	记载页码
					90°	100°	180°	270°	280°					
标准型		RV3S1	单电控	0.12	●		●	●		○	○	○		1338
		RV3D1	双电控	0.28	●					○	○	○		
		RV3S3	单电控	0.31	●		●	●		●	○	○		
		RV3D3	双电控	0.71	●					●	○	○		
		RV3S10	单电控	0.98	●		●	●		●	○	○		
		RV3D10	双电控	2.11	●					●	○	○		
		RV3S20	单电控	1.70	●		●	●		●	○	○		
		RV3D20	双电控	3.88	●					●	○	○		
		RV3S30	单电控	3.19	●		●	●		●		○	○	
		RV3D30	双电控	7.70	●					●		○	○	
带阀型		RV3S _W 10	单电控	0.98	●		●	●		●		○	○	1350
		RV3D _W 10	双电控	2.11	●					●		○	○	
		RV3S _W 20	单电控	1.70	●		●	●		●		○	○	
		RV3D _W 20	双电控	3.88	●					●		○	○	
		RV3S _W 30	单电控	3.19	●		●	●		●		○	○	
		RV3D _W 30	双电控	7.70	●					●		○	○	
角度可変型		RV3SA3	单电控	0.31			● (30~180°可変)			●		○	○	1354
		RV3DA3	双电控	0.71	● (30~90°可変)					●		○	○	
		RV3SA10	单电控	0.98			● (30~180°可変)			●		○	○	
		RV3DA10	双电控	2.11	● (30~90°可変)					●		○	○	
		RV3SA20	单电控	1.70			● (30~180°可変)			●		○	○	
		RV3DA20	双电控	3.88	● (30~90°可変)					●		○	○	
		RV3SA30	单电控	3.19				● (30~270°可変)		●		○	○	
		RV3DA30	双电控	7.70	● (30~90°可変)					●		○	○	

● 大型 (RV3※50~RV3※800)

● : 标准、○ : 准标准、■ : 不可制作

种类	型号		叶片型	有效扭矩 (0.5MPa时) (N·m)	摆动角度					带开关	气口位置 轴向	带法兰 部件	带脚座 部件	带缓冲器	记载页码
					90°	100°	180°	270°	280°						
标准型		RV3S50	单电控	4.7	●	■	●	●	●	●	■	○	○	○	1364
		RV3D50	双电控	10.1	●	●	■	■	■	●	■	○	○	○	
		RV3S150	单电控	14.7	●	■	●	●	●	●	■	○	○	○	
		RV3D150	双电控	34.3	●	●	■	■	■	●	■	○	○	○	
		RV3S300	单电控	27.9	●	■	●	●	●	●	■	○	○	○	
		RV3D300	双电控	66.6	●	●	■	■	■	●	■	○	○	○	
		RV3S800	单电控	102	●	■	●	●	●	●	■	○	○	○	
		RV3D800	双电控	206	●	●	■	■	■	●	■	○	○	○	
带阀型		RV3S _W 50	单电控	4.7	●	■	●	●	●	●	■	○	○	○	1372
		RV3D _W 50	双电控	10.1	●	●	■	■	■	●	■	○	○	○	
		RV3S _W 150	单电控	14.7	●	■	●	●	●	●	■	○	○	○	
		RV3D _W 150	双电控	34.3	●	●	■	■	■	●	■	○	○	○	
		RV3S _W 300	单电控	27.9	●	■	●	●	●	●	■	○	○	○	
		RV3D _W 300	双电控	66.6	●	●	■	■	■	●	■	○	○	○	
低油压型		RV3SH50	单电控	4.7	●	■	●	●	●	●	■	○	○	○	1378
		RV3DH50	双电控	10.1	●	●	■	■	■	●	■	○	○	○	
		RV3SH150	单电控	14.7	●	■	●	●	●	●	■	○	○	○	
		RV3DH150	双电控	34.3	●	●	■	■	■	●	■	○	○	○	
		RV3SH300	单电控	27.9	●	■	●	●	●	●	■	○	○	○	
		RV3DH300	双电控	66.6	●	●	■	■	■	●	■	○	○	○	
		RV3SH800	单电控	102	●	■	●	●	●	●	■	○	○	○	
		RV3DH800	双电控	206	●	●	■	■	■	●	■	○	○	○	
缓冲器		RVC50			●	●	●	●	●						1382
		RVC150			●	●	●	●	●						
		RVC300			●	●	●	●	●						

LCM
LCR
LCG
LCW
LCX
STM
STG
STS·STL
STR2
UCA2
ULK※
JSK/M2
JSG
JSC3·JSC4
USSD
UFCD
USC
UB
JSB3
LMB
LML
HCM
HCA
LBC
CAC4
UCAC2
CAC-N
UCAC-N
RCS2
RCC2
PCC
SHC
MCP
GLC
MFC
BBS
RRC
GRC
RV3※
NHS
HRL
LN
卡爪
卡盘
机械卡爪·卡盘
缓冲器
FJ
FK
速度控制器
卷末