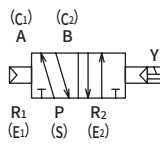
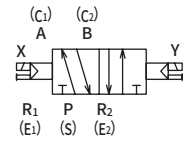
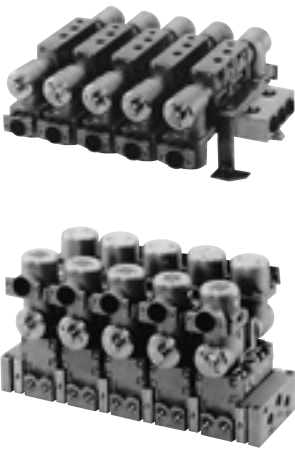
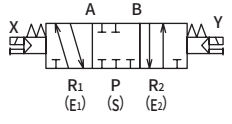
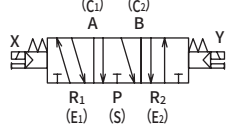
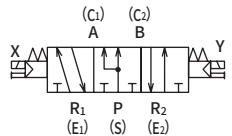


4GA/B
M4GA/B
MN4GA/B
4GA/B (气控阀)
4GB 带传感器
4GD/E
M4GD/E
MN4GD/E
4GA4/B4
MN3E MN4E
W4GA/B2
W4GB4
MN3S0 MN4S0
4SA/B0
4KA/B
4KA/B (气控阀)
4F
4F (气控阀)
PV5G GMF
PV5 GMF
PV5S-0
3Q
MV3QR
3MA/B0
3PA/B
P・M・B
NP・NAP NVP
4G※0EJ
4F※0EX
4F※0E
HMV HSV
2QV 3QV
SKH
消音器
全气动系统 (全空压)
全气动系统 (V)
卷末

系列外观	机种型号	位置 线圈数 JIS符号	流量特性		适用 缸径
			C (dm ³ /(s・bar)) 注1	有效 截面积 S (mm ²)	
4F※※0E 	直接型	4F3※0E	● 2位・单电控	3.9 ∩ 5.8	— φ63 ∩ φ100
	5通 底板型	4F4※0E		5.0 ∩ 5.3	— φ63 ∩ φ100
		4F5※0E	● 2位・双电控	9.7 ∩ 10	— φ80 ∩ φ160
		4F6※0E		15 ∩ 18	— φ140 ∩ φ200
		4F7※0E	● 3位・中封	—	160 φ180 ∩ φ250
M4F※※0E 	直接型	M4F3※0E		3.9 ∩ 5.8	— φ63 ∩ φ100
	5通 底板型	M4F4※0E	● 3位・ABR连接	5.0 ∩ 5.3	— φ63 ∩ φ100
		M4F5※0E		9.7 ∩ 10	— φ80 ∩ φ160
		M4F6※0E	● 3位・PAB连接	15 ~ 18	— φ140 ∩ φ200
		M4F7※0E		—	160 φ180 ∩ φ250

注1：有效截面积S与音速率C的换算公式为 $S \approx 5.0 \times C$ 。

	切换位置						A・B气口配管口径						选择项		绝缘等级		选型 页码
	2 位 单 电 控	2 位 双 电 控	3 位 中 封	3 位 A・B・R 连接	3 位 P・A・B 连接	混 合 型	内螺纹						外部导线引入		A	H	
							RP 1 / 4	RP 3 / 8	RC 1 / 4	RC 3 / 8	RC 1 / 2	RC 3 / 4	耐 压 密 封 件 保 护 管 螺 纹 旋 入 式 GP	电 线 管 螺 纹 结 合 方 式 TP			
	●	●	●	●	●		●	●					●	●	●	●	1810
	●	●	●	●	●				●	●			●	●	●	●	
	●	●	●	●	●					●	●		●	●	●	●	
	●	●	●	●	●						●	●	●	●	●	●	
	●	●	●	●	●							●	●	●	●	●	
	●	●	●	●	●	●	●	●					●	●	●	●	1824
	●	●	●	●	●	●			●				●	●	●	●	
	●	●	●	●	●	●				●			●	●	●	●	
	●	●	●	●	●	●					●		●	●	●	●	
	●	●	●	●	●	●						●	●	●	●	●	

4GA/B
M4GA/B
MN4GA/B
4GA/B
(气控阀)
4GB
带传感器
4GD/E
M4GD/E
MN4GD/E
4GA4/B4
MN3E
MN4E
W4GA/B2
W4GB4
MN3S0
MN4S0
4SA/B0
4KA/B
4KA/B
(气控阀)
4F
4F
(气控阀)
PV5G
GMF
PV5
GMF
PV5S-0
3Q
MV3QR
3MA/B0
3PA/B
P・M・B
NP・NAP
NVP
4G※0EJ
4F※0EX
4F※0E
HMF
HSV
2QV
3QV
SKH
消音器
全气动系统
(全空压)
全气动系统
(V)
卷末