


适用于高压流体控制

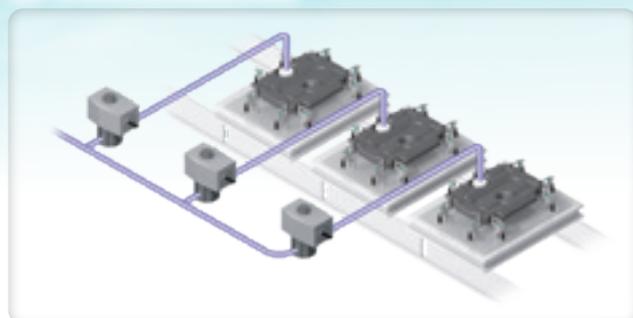


压力规格
15MPa

● 高压泄漏检查



● 高压清洗

示意图。

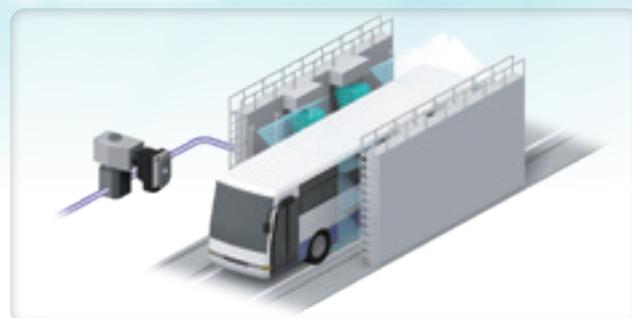

规格

机种	A2-6804	A2-6805
动作方式	直动式	先导式
配管口径	Rc1/8	Rc3/8
使用流体	水、油 (50mm ² /s以下) ※1	
耐压力 MPa	25 (水压)	
最高使用压力 MPa	15.0	
动作压力差 MPa	—	0.1~15
流体温度 °C	-10~60 (不得冻结)	
环境温度 °C	-10~60	
内部泄漏 cm ³ /min	0 (水压: 0.1~15MPa)	
额定电压 V	DC24V±10%	AC100V±10%
功耗 W	10.4	6.7/5.7 (50Hz/60Hz)
视在功率 VA	—	保持时: 18/15 启动时: 29/24
额定	间歇额定 通电duty比: 50%以下	
阀体·密封件材质	阀体: 不锈钢 主阀体: PCTFE	
通径 mm	1	6
重量 kg	0.7	0.85

※1: 关于其他流体, 请咨询本公司。

※2: 详情请确认规格书。

高压用2通电磁阀 A2-6804/A2-6805

CKD Corporation


<https://www.ckd.sh.cn/>

LN-003C

●本产品为特殊规格产品, 请垂询本公司营业担当。


A2-6804/A2-6805

A2-6804 直动式

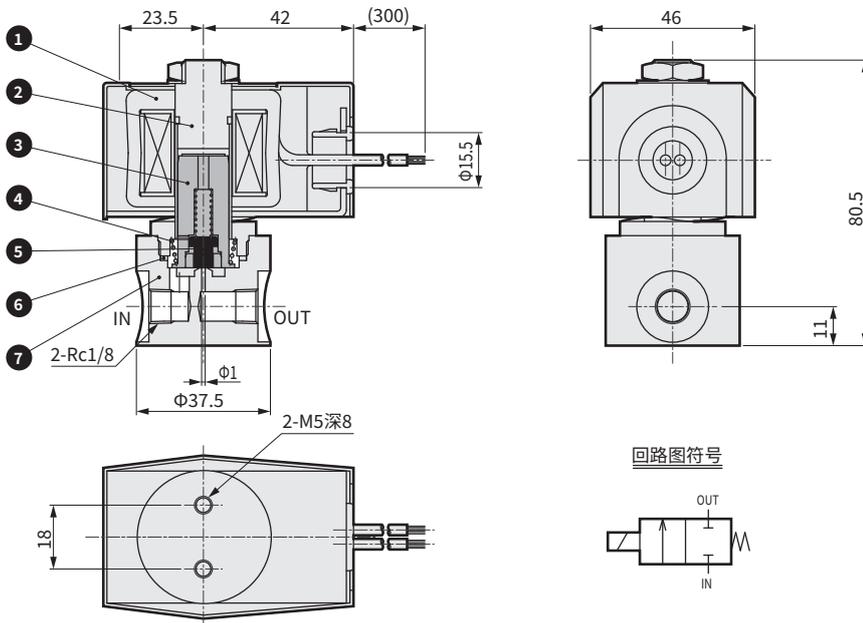

编号	部件名称	材质
1	线圈	-
2	静铁芯组件	SUS405 相当 · 316L · 304 不锈钢 (电镀)
3	动铁芯	SUS405 相当 不锈钢
4	弹簧	SUS303 不锈钢
5	阀体	PCTFE 三氟乙烯
6	密封垫	HNBR 氯化丁腈橡胶
7	本体	SUS303 不锈钢

A2-6805 先导式

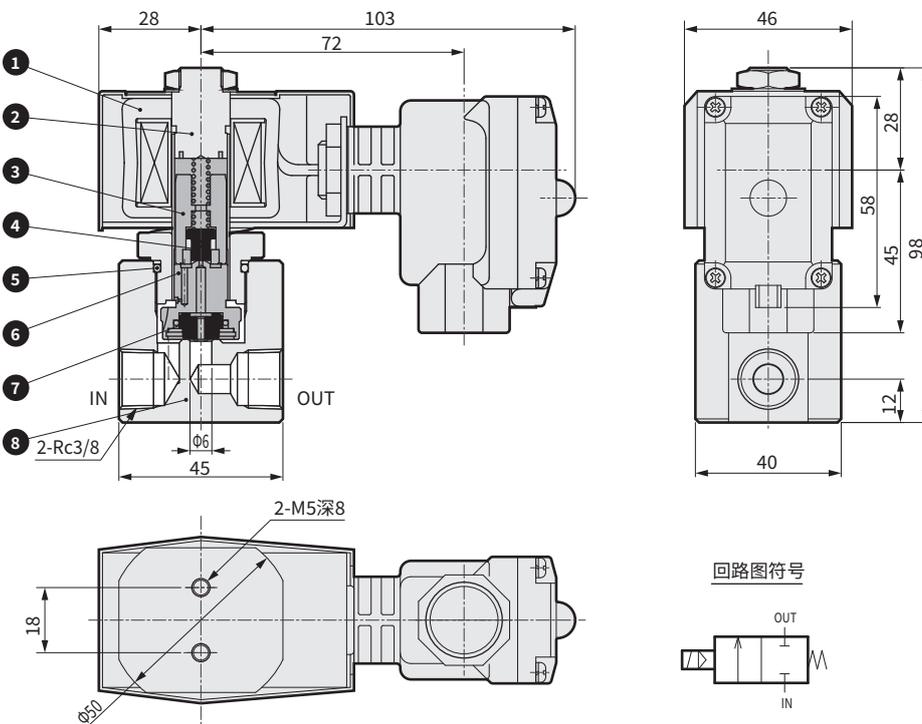

编号	部件名称	材质
1	线圈	-
2	静铁芯组件	SUS405 相当 · 316L · 304 不锈钢 (电镀)
3	动铁芯	SUS405 相当 不锈钢
4	阀体	PCTFE 三氟乙烯
5	密封垫	HNBR 氯化丁腈橡胶
6	阀体	SUS304 不锈钢
7	主阀体	PCTFE 三氟乙烯
8	本体	SUS303 不锈钢

需从日本出口本产品及其相关技术或软件时，根据日本法律请务必注意防止将其用于与军火、武器相关的用途中。
If the goods and/or their replicas, the technology and/or software found in this catalog are to be exported from Japan, Japanese laws require the exporter makes sure that they will never be used for the development and/or manufacture of weapons for mass destruction.

喜开理(上海)机器有限公司 营业本部

<Website>
<https://www.ckd.sh.cn/>

上海市徐汇区虹梅路1905号远中科研大楼6楼601 200233
电话 (021) 61911888 传真 (021) 60905357

●出于改良的目的，本样本上记载的产品规格及外观可能会进行变更，恕不另行通知，敬请谅解。
©CKD Corporation 2023 All copy rights reserved.
©喜开理(上海)机器有限公司 2023版权所有



官方微信

2023.2