


以标签为证,让安全可见

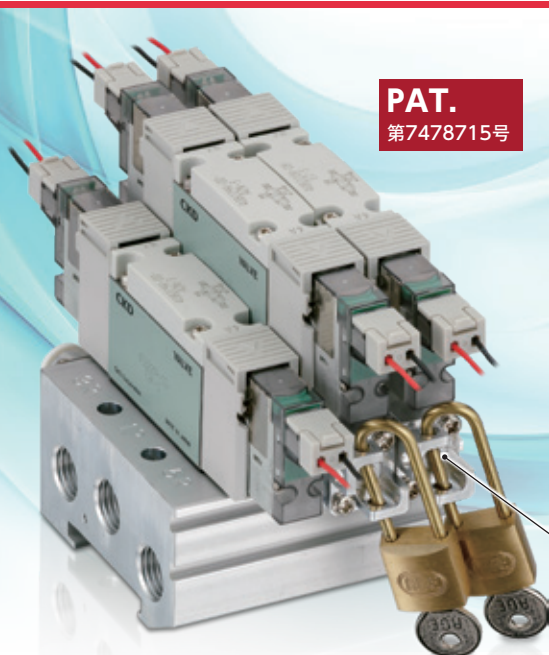

特点

- 手动操作强制保持阀的输出
- 可通过锁紧管理防止手动误操作的安全结构。(符合LOTO标准)
- 采用隔板结构,便于增减阀的连数。

带LOTO功能 进气截止阀隔板

※不附带挂锁。

什么是LOTO功能?

锁定挂牌(Lockout/Tagout)是保护进行机械设施操作、服务、检查及维护的员工安全的重要手段,同时用于证明和明确动力源已被切断。

【锁定】

在对机械设备进行检修和维护时,需先切断断路器、开关、阀等动力源,然后安装锁定装置并上锁。


【挂牌】

作为警告标签的一种,需在已被锁定装置锁定的安全位置悬挂警告标签,在标签被拆除前,机械设备不得重新启动。


动作原理

LOTO无效


当LOTO隔板处于手动关闭状态时,阀可正常动作。

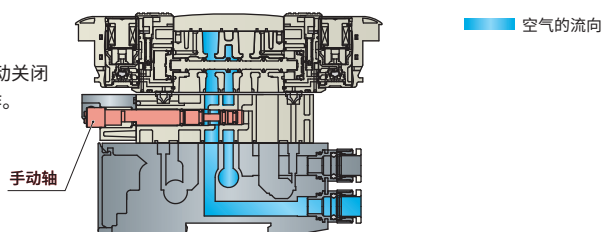

LOTO有效

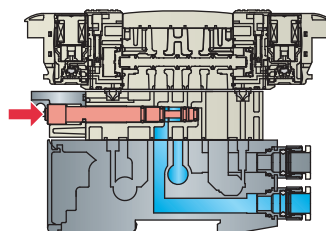

操作LOTO隔板的手动装置,可强制保持阀二次侧的输出压力。(即使一次侧压力消除仍能保持)。

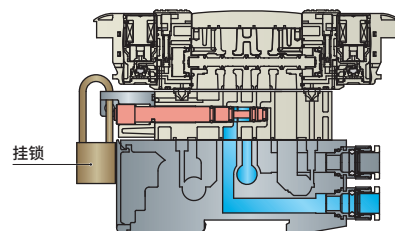

LOTO隔板的手动操作部件可通过挂锁等进行上锁管理,防止因意外操作导致的误动作。

带LOTO功能进气截止阀隔板 M4GB2/MN4GB2系列

CKD Corporation

<https://www.ckd.co.jp/zh/>

LN-020CS

●本产品为特殊规格产品,请垂询本公司营业担当。

M4GB2/MN4GB2 Series

型号表示方法

■M4GB2R系列、MN4GB2R系列



※1. “※”表示选择订购型号后，本公司将填写6位数的字符。
※2. 有关M4GB2系列、MN4GB2系列的详情（规格、型号等），请参阅《方向控制阀①》（样本编号：RJ-011CS）。



规格


通用规格

项 目	内 容
使用流体	压缩空气
最低使用压力 MPa	0.2
最高使用压力 MPa	0.7
耐压力 MPa	1.05
给油	不可
防护等级	防尘
使用温度 °C	-5~55
流体温度 °C	5~55
耐振动 m/s ²	50以下
耐冲击 m/s ²	300以下
环境	不可在腐蚀性气体环境中使用

带LOTO功能进气截止阀隔板规格


项 目	内 容
锁孔尺寸	φ3.8
流量特性	流路：1→2/4
dm ³ /bar·sec	流路：2/4→3/5

回路图符号

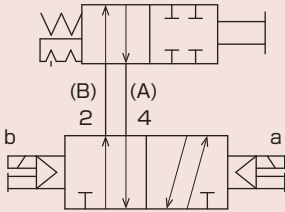


外形尺寸图

●M4GB2

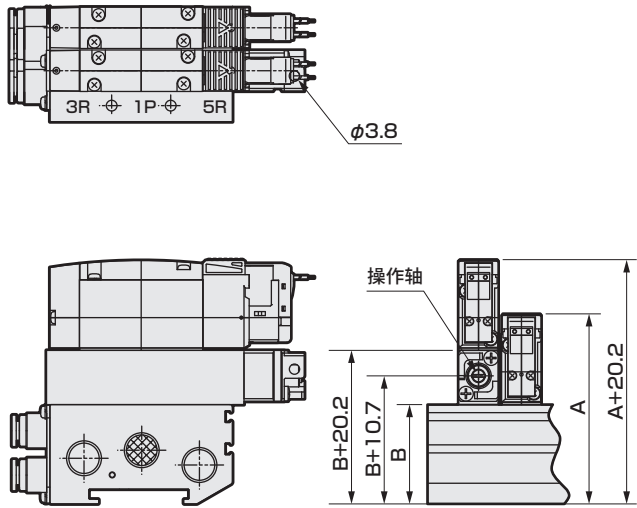

●MN4GB2

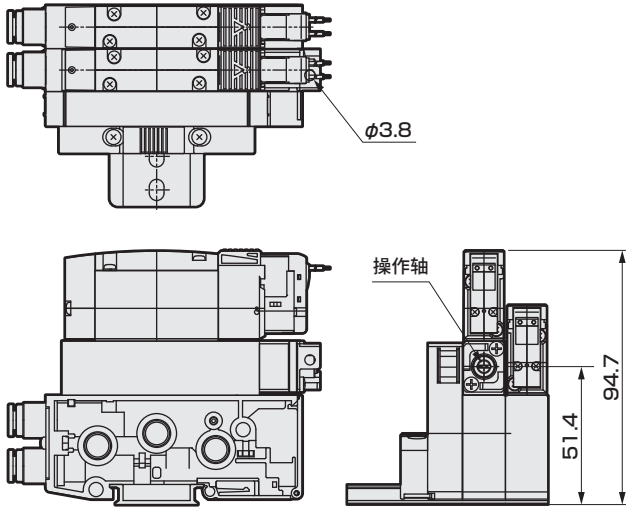

注：A、B尺寸请确认M4GB2、MN4GB2系列各规格的外形尺寸图。

需从日本出口本产品及其相关技术或软件时，根据日本法律请务必注意防止将其用于与军火、武器相关的用途中。
If the goods and/or their replicas, the technology and/or software found in this catalog are to be exported from Japan, Japanese laws require the exporter makes sure that they will never be used for the development and/or manufacture of weapons for mass destruction.

喜开理(上海)机器有限公司 营业本部

<Website>

<https://www.ckd.sh.cn/>

●出于改良的目的，本样本上记载的产品规格及外观可能会进行变更，恕不另行通知，敬请谅解。
©CKD Corporation 2025 All copy rights reserved.
©喜开理（上海）机器有限公司 2025版权所有

上海市徐汇区虹梅路1905号远中科研大楼6楼601
电话（021）61911888 传真（021）60905357

200233



官方公众号



官方视频号

2025.9